



ZK2.5-4P PI-Spring terminal blocks

Feed-through with 4 connections - 5.2 mm 0.205 in spacing

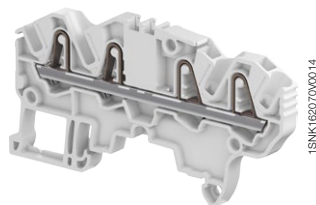

ZK2.5-4P

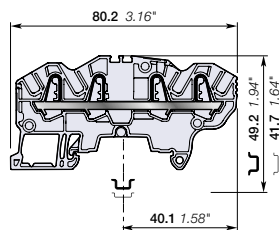

5.2 mm 0.205 in spacing

Description

Find all the features of the ZK2.5 terminal block with the added option of distributing or branching 4 conductors.

Ordering details

Description	Color	Type	Order code	Pkg qty	Weight (1 pce) g
Feed-through 4 connections	Grey	ZK2.5-4P	1SNK705012R0000	50	9.00
	Blue	ZK2.5-4P-BL	1SNK705022R0000	50	9.00
	Orange	ZK2.5-4P-OR	1SNK705032R0000	50	9.00
	Yellow	ZK2.5-4P-YL	1SNK705074R0000	50	9.00
	Green	ZK2.5-4P-GN	1SNK705075R0000	50	9.00
	Red	ZK2.5-4P-RD	1SNK705076R0000	50	9.00
	White	ZK2.5-4P-WH	1SNK705079R0000	50	9.00
	Black	ZK2.5-4P-BK	1SNK705080R0000	50	9.00

Main technical data

Connecting capacity		IEC	UL - CSA
1 conductor per clamp	Rigid - Solid / Stranded	0.2 ... 4 mm²	26 ... 12 AWG
	Flexible	0.22 ... 2.5 mm²	26 ... 14 AWG
	with non insulated ferrule	0.22 ... 2.5 mm²	26 ... 14 AWG
	with insulated ferrule	0.22 ... 2.5 mm²	26 ... 14 AWG
2 conductors per clamp		Flexible with twin ferrule	0.22 ... 0.5 mm² 26 ... 20 AWG
Rated current / Rated cross section		24 A / 2.5 mm²	20 A / 12 AWG
Rated short-time withstand current (1s)		300 A	396 A
Short Circuit Current Rating (with specific conditions)			100 kA
Rated voltage		1000 V	600 V
Impulse withstand voltage		8000 V	
Protection		IP20	NEMA 1
Increased safety Ex e		693 V 21 A IEC/EN 60079-7 - IM2 II 2 GD Ex eb I/IC/IIIC	

The connecting capacity data for one Rigid - Solid / Stranded - Flexible conductor (when applicable) is a mandatory information required by IEC, UL and CSA standards (Copper conductors). All other data are provided as supplementary information only. For more details, please consult our CB, UL or CSA certificates and technical datasheet available on <http://www.ABB.com>



Mounting instructions

Rail		TH 35-7.5, TH 35-15
Wire stripping length		11 mm 0.433 in
Tool (for flexible conductor without ferrule)		Flat screwdriver Ø 3.5 mm Ø 0.138 in

Accessories

Description				Color	Type	Order code	Pkg	Weight
							qty	(1 pce) g
1	End stops	5.2 mm	0.205 in	Dark grey	BAZ1	1SNK900002R0000	50	5.30
2	End sections	2 mm	0.079 in	Dark grey	EK2.5-4P	1SNK705912R0000	20	2.70
3	Jumper bars	2 poles	32 A (IEC)	Orange	JB5-2	1SNK905302R0000	50	1.30
		3 poles	32 A (IEC)		JB5-3	1SNK905303R0000	50	2.00
		4 poles	32 A (IEC)		JB5-4	1SNK905304R0000	50	2.70
		5 poles	32 A (IEC)		JB5-5	1SNK905305R0000	50	3.50
		10 poles	32 A (IEC)		JB5-10	1SNK905310R0000	30	7.10
		50 poles	32 A (IEC)		JB5-50	1SNK905350R0000	10	36.00
4	Cross spacing jumpers	3 poles	32 A (IEC)	Orange	JB85-3	1SNK900603R0000	10	2.80
5	Circuit separators	3 mm	0.118 in	Dark grey	CS-R3	1SNK900107R0000	20	6.40
6	Test adapters	For test plugs DIA 2 mm 0.079 in		Dark grey	TP2	1SNK900203R0000	20	1.70
		For test plugs DIA 4 mm 0.157 in			TP4	1SNK900205R0000	20	2.40
7	Test connectors	5.2 mm 0.205 in spacing		Dark grey	TC5	1SNK900200R0000	10	5.20
		End module, 5.2 mm 0.205 in			TC5-R1	1SNK900201R0000	10	5.20
8	Terminal block markers	Blank marker		White	MG-CPM 13 41790	1SNB041790R0512	1960	0.23
		Blank card			MC512	1SNK140000R0000	22	9.00
					MC512PA	1SNK149999R0000	20	10.00
		Universal wire markers holder		Grey	UMH	1SNK900611R0000	10	0.20

Complete list of accessories is indicated in the terminal block datasheet including end stops.

Some accessories such as jumper bars may modify the terminal block's ratings: Complete information available in the accessories section of the catalog.

Ground PI-Spring terminal blocks

Description	Color	Type	Order code	Pkg qty	Weight (1 pce) g
Ground Profile aligned with ZK2.5-4P	Green-yellow	ZK2.5-PE-4P	1SNK705152R0000	20	13.60

All the technical data for UL/CSA standard and dimensions in inches are in *italic*.

Technical data valid for copper conductors only.