
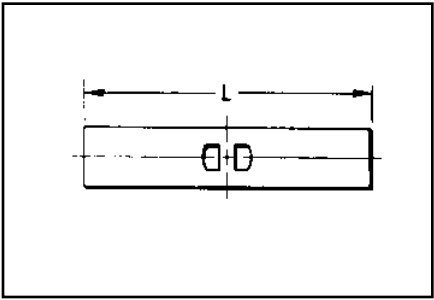


TYPE YSV-L

HYLINK™

Uninsulated Butt Splice
600 Volts Maximum
#8 Through 4/0 Copper

HYLINK™ type YSV-L seamless splice connector is used to splice Type AN aircraft cables plus commercial stranded and solid AWG conductors. Suitable for aircraft, light duty industrial and general purpose applications.

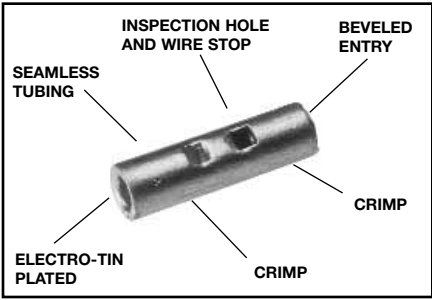

Catalog Number	Wire Range Aircraft-AN" Comm'I-AWG Str. & Sol.	Dimensions L	Bulk Catalog Number	Installation Tooling				Y34PA Wire Strip Length
				Ratchet	HYTOOL™ **	HYPRESS™• H35, Y35BH, Y39, Y39BH*		
						Nest	Indenter	
YSV8C-L BOX	8	1.00	YSV8C-L	MR89Q, Y8MRB-1, Y1MRTC	Type AH Aircraft Cable: MY28	UV8L-1	Y34PL	7/16"
YSV6C-L BOX	6	1.12	YSV6C-L	Y1MRTC, MR4C		UV6L	Y34PLA	1/2"
YSV4C-L BOX	4	1.12	YSV4C-L	Y1MRTC, MR4C		UV4L		5/8"
YSV2C-L BOX	2	1.41	YSV2C-L	Y1MRTC		UV2L		5/8"
YSV1C-L BOX	1	1.46	YSV1C-L	—	All Others: MY29-3, MY29-11 1 Crimp	UV1L	Y34PA	5/8"
YSV25-L BOX	1/0	1.53	YSV25-L	—		UV25L		11/16"
YSV26-L BOX	2/0	1.78	YSV26-L	—		UV26L		13/16"
YSV27-L BOX	3/0	1.81	YSV27-L	—		UV27L		13/16"
YSV28-L BOX	4/0	1.94	YSV28-L	—		UV28L		7/8"

* Remove stop plate
• Use Y35P3 Indenter Adaptor.
** Bench Mount Adaptor - Cat. No. BMY-BCH-MT is available for Type MY HYTOOLS™.