


Class gG IEC 60269 industrial ferrule fuses

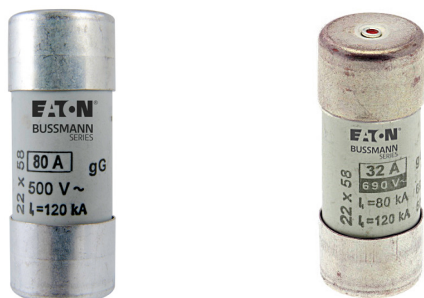

8 to 22mm diameter IEC Class gG fuses with optional indicators and strikers. See catalog numbers for availability and ratings.

8x31mm, Class gG, 400 Vac, 0.5 to 20 A

Catalog no.				
Without indicator	With indicator	Vac	Amps	IR (kA)
C08G0.5	—	400	0.5	20
C08G1	—		1	
C08G2	C08G2I		2	
C08G4	C08G4I		4	
C08G6	C08G6I		6	
C08G8	C08G8I		8	
C08G10	C08G10I		10	
C08G12	C08G12I		12	
C08G16	C08G16I		16	
C08G20	C08G20I		20	

10x38mm, Class gG, 500 and 400 Vac, 0.5 to 32 A

Catalog no.					
W/O indicator	W/ indicator	Vac	Amps	IR (kA)	Holder/block
C10G0.5	—	500	0.5	120	CHM DIN-Rail*, BMM block
C10G1	C10G1I		1		
C10G2	C10G2I		2		
C10G4	C10G4I		4		
C10G6	C10G6I		6		
C10G8	C10G8I		8		
C10G10	C10G10I		10		
C10G12	C10G12I		12		
C10G16	C10G16I		16		
C10G20	C10G20I		20		
C10G25	C10G25I		25		
C10G32	C10G32I	400	32	120	
C10G32	—	400	32		
—	C10G32I	500	32		
—	C10G40I	500	40		
—	C10G50I	400	50		

* Not recommended for use with indicator version.

14x51mm, Class gG, 400, 500 and 690 Vac, 1 to 50 A

Catalog no.					
W/O indicator	W/ indicator	W/ striker	Vac	Amps	IR (kA) Holder
C14G1	C14G1I	—	690	1	80
C14G2	C14G2I	—		2	120
—	—	C14G2S	500	—	80
C14G4	C14G4I	—	500	4	120
—	—	C14G4S	500	—	80
C14G6	C14G6I	—	690	6	120
—	—	C14G6S	500	—	80
C14G8	C14G8I	—	690	8	120
—	—	C14G8S	500	—	80
C14G10	C14G10I	—	690	10	120
—	—	C14G10S	500	—	80
C14G12	C14G12I	—	690	12	120
—	—	C14G12S	500	—	80
C14G16	C14G16I	—	690	16	120
—	—	C14G16S	500	—	80
C14G20	C14G20I	—	690	20	120
—	—	C14G20S	500	—	80
C14G25	C14G25I	—	690	25	120
—	—	C14G25S	500	—	80
C14G32	C14G32I	C14G32S	500	32	120
C14G40	C14G40I	C14G40S		40	
C14G50	C14G50I	C14G50S		50	

CH14 DIN-Rail**


**Not recommended for use with indicator version, use striker version to actuate optional, external microswitch

22x58mm, Class gG, 400, 500 and 690 Vac, 2 to 125 A

Catalog no.					
W/O indicator	W/ indicator	W/ striker	Vac	Amps	IR (kA) Holder/block
C22G2	C22G2I	—	690	2	80 CH22 DIN-Rail*, JM70100 block
C22G4	C22G4I	C22G4S		4	
C22G6	C22G6I	C22G6S		6	
C22G8	C22G8I	C22G8S		8	
C22G10	C22G10I	C22G10S		10	
C22G12	C22G12I	C22G12S		12	
C22G16	C22G16I	C22G16S		16	
C22G20	C22G20I	C22G20S		20	
C22G25	C22G25I	C22G25S		25	
C22G32	C22G32I	C22G32S		32	
C22G40	C22G40I	C22G40S		40	
C22G50	C22G50I	C22G50S		50	
C22G63	C22G63I	C22G63S	500	63	120
C22G80	C22G80I	C22G80S		80	
C22G100	C22G100I	C22G100S		100	
C22G125	C22G125I	C22G125S	400	125	

* Not recommended for use with indicator version, use striker version to actuate optional, external microswitch.

Dimensions — mm

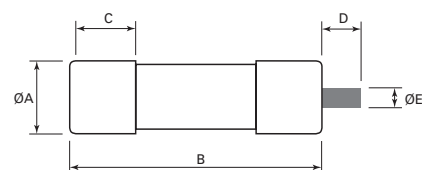

Catalog symbol	Ø A	B	C	Indicator/striker	
				D	Ø E
C08M	8	31.5	6.3	—	—
C10M	10	38	10	—	—
C14M	14.3	51	13	8	4
C22M	22	58	16	8	4