


GRADE 2 FULLY THREADED MACHINE TAP BOLTS • ZINC

			Best Merchandising Option			
	 Cardboard Box		 Gravity Feed Jar		 Job Jar	
Size	Part #	Qty	Part #	Jar Qty/ Std Pk	Part #	Jar Qty
¼-20 x 1¼	55022	100	55022J	100/600	—	—
¼-20 x 1½	55026	100	55026J	100/600	—	—
¼-20 x 2	55034	100	▲		—	—
¼-20 x 2½	55035	100	▲		—	—
¼-20 x 3	55050	100	▲		—	—
⅝-18 x 1	55216	100	▲		—	—
⅝-18 x 1½	55227	100	▲		—	—
⅝-18 x 2	55234	100	▲		—	—
⅝-18 x 2½	55242	100	▲		—	—
⅜-16 x 1¼	55422	100	55422J	100/600	—	—
⅜-16 x 2	55434	50	▲		—	—
⅜-16 x 2½	55442	50	▲		—	—
⅜-16 x 3	55450	50	▲		—	—
½-13 x 1	55816	50	▲		—	—
½-13 x 1¼	55822	50	55822J	50/300	—	—
½-13 x 1½	55826	50	▲		—	—
½-13 x 2	55834	50	▲		—	—
½-13 x 2½	55842	50	▲		—	—
½-13 x 3	55850	50	▲		—	—

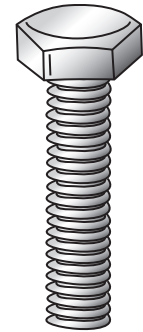


▲ Contact customer service for gravity feed jar availability.

For bulk packaging, contact customer service for quantities and availability.

GRADE 2 HEX HEAD MACHINE BOLTS • ZINC

- 1", ¾" and ½" are fully threaded.
- No markings and made of low grade carbon steel.

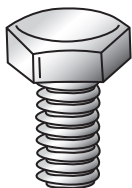

▲ Contact customer service for gravity feed jar availability.

For bulk packaging, contact customer service for quantities and availability.

			Best Merchandising Option			
			 Cardboard Box	 Gravity Feed Jar	 Job Jar	
Size	Part #	Qty	Part #	Jar Qty/ Std Pk	Part #	Jar Qty
¼-20 x ½	55008	100	55008J	100/1200	—	—
¼-20 x ¾	55012	100	55012J	100/600	—	—
¼-20 x 1	55016	100	55016J	100/600	—	—
¼-20 x 1¼	55020	100	55020J	100/600	—	—
¼-20 x 1½	55024	100	55024J	100/600	—	—
¼-20 x 2	55032	100	55032J	100/600	—	—
¼-20 x 2½	55040	100	55040J	100/600	—	—
¼-20 x 3	55048	100	55048J	100/600	—	—
¼-20 x 3½	55056	50	▲		—	—
¼-20 x 4	55064	50	▲		—	—
⅝-18 x ½	55208	100	▲		—	—
⅝-18 x ¾	55212	100	55212J	100/600	—	—
⅝-18 x 1	55216	100	55216J	100/600	—	—
⅝-18 x 1¼	55220	100	55220J	100/600	—	—
⅝-18 x 1½	55224	100	55224J	100/600	—	—
⅝-18 x 2	55232	100	▲		—	—
⅝-18 x 2½	55240	100	55240J	100/600	—	—
⅝-18 x 3	55248	100	55248J	100/600	—	—
⅝-18 x 3½	55256	50	▲		—	—
⅝-18 x 4	55264	50	▲		—	—
⅜-16 x ½	55408	100	55408J	100/600	—	—
⅜-16 x ¾	55412	100	55412J	100/600	—	—
⅜-16 x 1	55416	100	55416J	100/600	—	—
⅜-16 x 1¼	55420	100	55420J	100/600	—	—
⅜-16 x 1½	55424	100	55424J	100/600	—	—
⅜-16 x 2	55432	50	55432J	100/600	—	—
⅜-16 x 2½	55440	50	55440J	50/300	—	—
⅜-16 x 3	55448	50	55448J	50/300	—	—
⅜-16 x 3½	55456	50	55456J	50/300	—	—
⅜-16 x 4	55464	50	55464J	50/300	—	—
½-13 x ¾	55812	50	55812J	50/300	—	—
½-13 x 1	55816	50	55816J	50/300	—	—
½-13 x 1¼	55820	50	55820J	50/300	—	—
½-13 x 1½	55824	50	55824J	50/300	—	—
½-13 x 2	55832	50	55832J	50/300	—	—
½-13 x 2½	55840	50	55840J	50/300	—	—
½-13 x 3	55848	50	55848J	50/300	—	—
½-13 x 3½	55856	25	55856J	25/150	—	—
½-13 x 4	55864	25	55864J	25/150	—	—