



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT(lbs.)	(in inches) A B	
Rigid Couplings				STEEL	
1/2"	64005B	100	12	1.010	1.625
3/4"	64007B	50	9	1.250	1.640
1"	64010	10	3.2	1.525	1.970
1 1/4"	64012	5	2.1	1.869	2.030
1 1/2"	64015	5	2.9	2.155	2.060
2"	64020	4	3.2	2.650	2.125
2 1/2"	64025	1	1.7	3.250	3.190
3"	64030	1	2.1	3.870	3.315
3 1/2"	64035	1	3.4	4.500	3.410
4"	64040	1	3	4.875	3.515



Application: Indoors or Outdoors. Use to join threaded Rigid or IMC conduit together.
Material: Galvanized Steel

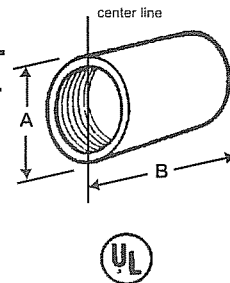


				A	Min. UL Radius	B
90° Rigid Elbows				STEEL		
1/2"	64105B	50	40	4.000	6.375	1.750
3/4"	64107B	50	54	4.500	7.438	2.250
1"	64110B	20	40	5.750	9.500	2.250
1 1/4"	64112B	20	60	7.250	11.375	3.000
1 1/2"	64115B	10	42	8.250	12.813	3.500
2"	64120B	10	68	9.500	15.500	4.000
2 1/2"	64125	1	12	10.500	19.250	4.750
3"	64130	1	19	13.000	21.500	6.000
3 1/2"	64135	1	28	15.000	24.500	5.500
4"	64140	1	31	16.000	25.500	5.750

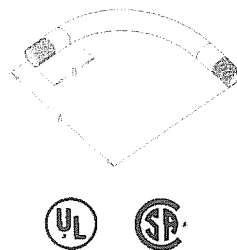

Application: Indoors or Outdoors. Use to allow a 90° change of direction in a run of Rigid or IMC conduit. **Material:** Galvanized Steel



				A	Min. UL Radius	B
45° Rigid Elbows				STEEL		
1/2"	64205	10	5.2	4.000	6.375	1.750
3/4"	64207	10	8.2	4.500	7.438	2.250
1"	64210	25	30	5.750	9.500	2.250
1 1/4"	64212	20	40	7.250	11.375	3.000
1 1/2"	64215	15	45	8.250	12.813	3.500
2"	64220	10	50	9.500	15.500	4.000

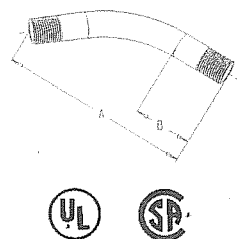

Application: Indoors or Outdoors. Use to allow a 45° change of direction in a run of Rigid or IMC conduit. **Material:** Galvanized Steel