

TRADE
SIZE

HALEX
PART #

CTN/CASE
QTY

CTN/CASE
WT(lbs.)

DIMENSIONS
(in inches)

A

B

C

One-Hole Straps

STEEL

1/2"	61505B	100/1000	3/25	1.250	0.562	
3/4"	61507B	100/1000	4/38	1.375	0.625	
1"	61510B	50/500	3/31.5	1.562	0.750	
1 1/4"	61512B	50/500	4/40	2.000	0.875	
1 1/2"	61515B	25/250	3/36.5	2.125	1.000	
2"	61520B	20/200	4/40	2.625	1.125	
2 1/2"	61125	10	4.3	3.312	1.250	
3"	61130	10	5	3.625	1.250	
3 1/2"	61135B	25	17.5	4.000	1.250	
4"	61140B	20	15.6	4.250	1.250	

* Not UL/CSA certified.

Application Indoors or Outdoors. To support EMT conduit where greater load bearing is required. **Material:** Steel, Zinc Electro-Plate **Type:** Snap-on Style





Two-Hole Straps

STEEL

1/2"	61605B	100/1000	2/18	2.250	1.625	0.562
3/4"	61607B	100/1000	2/25.5	2.750	2.125	0.625
1"	61610B	50/500	1.5/15.5	3.000	2.437	0.688
1 1/4"	61612B	25/250	1.5/14	3.750	2.937	0.750
1 1/2"	61615B	25/250	2/20	4.250	3.500	0.875
2"	61620B	50/200	7/28	4.812	4.000	1.000
2 1/2"	61225B	25	4.3	5.875	4.875	1.000
3"	61230	10	2.5	6.500	5.500	1.000
3 1/2"	61235B	25	6.5	7.375	6.375	1.000
4"	61240B	20	6.6	8.000	7.000	1.000

Application: Indoors or Outdoors. To support EMT conduit where greater load bearing is required. **Material:** Steel, Zinc Electro-Plate **Type:** Snap-on Style

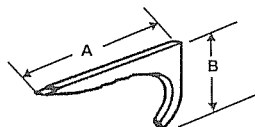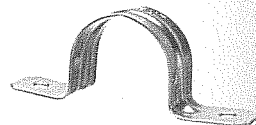

Drive Straps

STEEL

1/2"	61405B	100/1000	1.4/14	2.00	1.10	
3/4"	61407B	100/1000	1.6/16	2.12	1.20	
1"	61410B	100/1000	2.4/24	2.25	1.50	


Application: Indoors or Outdoors. To secure EMT conduit to a wood or masonry surface. **Material:** Steel, Zinc Electro-Plate **Type:** Flat Style






TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT(lbs.)	A	(in inches) B
One-Hole Straps				STEEL	
1/2"	61105B	100/1000	3/30	1.375	0.625
3/4"	61107B	100/1000	5/50	1.562	0.750
1"	61110B	50/500	3.5/35	1.812	0.875
1 1/4"	61112B	50/500	5/50	2.000	0.875
1 1/2"	61115B	25/250	4.25/42.5	2.500	1.000
2"	61120	10	2.5	2.750	1.125
2 1/2"	61125	10	4.3	3.312	1.250
3"	61130	10	5	3.625	1.250
3 1/2"	61135	25	17.8	4.000	1.250
4"	61140B	20	15.6	4.250	1.250

Application: Indoors or Outdoors. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **Material:** Steel, Zinc electro-plate

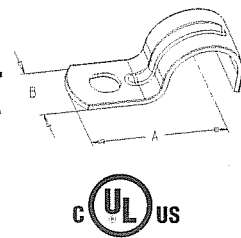


				A	B	C
Two-Hole Straps				STEEL		
1/2"	61205B	100/1000	2/20	2.250	1.625	0.562
3/4"	61207B	100/1000	3/30	2.875	2.250	0.638
1"	61210B	50/500	2.5/25	3.375	2.625	0.750
1 1/4"	61212B	25/250	1.75/17.5	4.188	3.437	0.875
1 1/2"	61215B	25/250	3/30	4.625	3.812	0.875
2"	61220B	50/200	7.5/30	5.125	4.250	1.000
2 1/2"	61225B	25	4.3	5.875	4.875	1.000
3"	61230	10	2.5	6.500	5.500	1.000
3 1/2"	61235B	25	6.5	7.375	6.375	1.000
4"	61240B	20	6.6	8.000	7.000	1.000

Application: Indoors or Outdoors. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **Material:** Steel, Zinc electro-plate

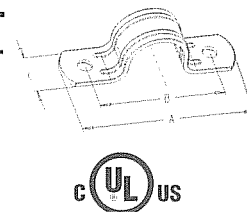


One-Hole Straps				MALLEABLE IRON		
1/2"	31205B	50/500	2.5/25	2.016	0.625	0.969
3/4"	31207B	50/500	3/30	2.219	0.750	1.031


Application: Indoors or Outdoors. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **Material:** Malleable Iron

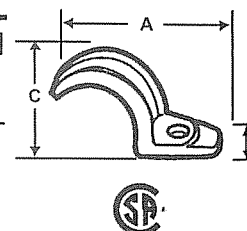

Clamp Backs				MALLEABLE IRON	
1/2"	33205B	25/250	2.5/25	2.297	1.031
3/4"	33207B	25/250	2.75/27.5	2.438	1.172

Application: Indoors or Outdoors. Use to provide spacing between mounting surface and Rigid conduit. **Material:** Malleable Iron

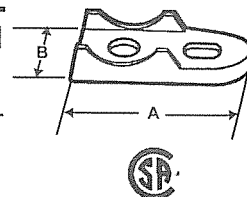

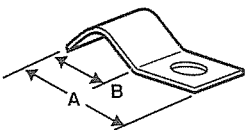

TRADE
SIZE

HALEX
PART #

CTN/CASE
QTY

CTN/CASE
WT(lbs.)

DIMENSIONS
(in inches)

A

B


Midget One-Hole Straps

STEEL

3/16" o.d.	26212	20 bags of 50 pcs	3	0.73	0.33
1/4" o.d.	26214	10 bags of 50 pcs	3	0.95	0.50

Application: Indoors or Outdoors. Use to secure bare solid copper wire to a working surface.

Material: Steel, Zinc Electro-Plate

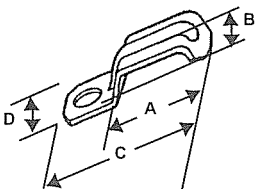

One-Hole Service-Cable Straps

STEEL


FITS NM CABLE

				A	B	C	D
#12/2-#14/2	62171B	100/1000	1/10	0.585	0.300	1.322	0.500

FITS SE AND SEU CABLE

3#8-3#4	62191B	100/1000	2/20	0.875	0.375	1.688	0.562
3#3-3#2	62192B	100/1000	2/20	1.000	0.500	1.937	0.562
3#1-3#2/0	62193B	25/250	1.8/17.5	1.250	0.750	2.500	1.000
3#3/0-3#4/0	62194B	25/250	2/20	1.500	0.812	2.812	1.000

 Application: Indoors or Outdoors. Use to secure service entrance cable (SEU, SE) to a wood, masonry or similar surface. **Material:** Steel, Zinc Electro-Plate



Two-Hole Service-Cable Straps

STEEL

FITS SE AND SEU CABLE

3#8-3#4	62291B	100/1000	3/30	0.875	0.375	2.375	0.750
3#3-3#2	62292B	100/1000	3/30	1.000	0.500	2.750	0.750
3#1-3#2/0	62293B	25/250	1/10	1.250	0.750	3.188	0.750
3#3/0-3#4/0	62294B	25/250	1/10	1.500	0.812	3.500	0.750

Application: Indoors or Outdoors. Use to secure service entrance cable (SEU, SER) to a wood, masonry or similar surface. **Material:** Steel, Zinc Electro-Plate

