


TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
One-Hole Straps			Steel		
1/2"	61105B	100/1000	3/30	1.375	0.625
3/4"	61107B	100/1000	5/50	1.562	0.750
1"	61110B	50/500	3.5/35	1.812	0.875
1 1/4"	61112B	50/500	5/50	2.000	0.875
1 1/2"	61115B	25/250	4.25/42.5	2.500	1.000
2"	61120	10	2.5	2.750	1.125
2 1/2"	61125	10	4.3	3.312	1.250
3"	61130	10	5	3.625	1.250
3 1/2"	61135B	25	17.8	4.000	1.250
4"	61140B	20	15.6	4.250	1.250

APPLICATION: INDOORS OR OUTDOORS. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **MATERIAL:** Steel, Zinc Electro-plate.
CERTIFICATIONS: TO UL AND CSA REQUIREMENTS.




TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C
One-Hole Straps				Malleable Iron		
1/2"	31205B	50/500	2.5/25	2.016	0.625	0.969
3/4"	31207B	50/500	3/30	2.219	0.750	1.031

APPLICATION: INDOORS OR OUTDOORS. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **MATERIAL:** Malleable Iron.
CERTIFICATIONS: TO UL AND CSA REQUIREMENTS.

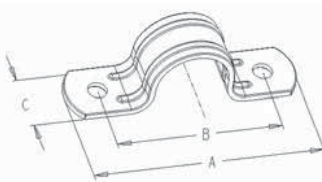

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C
Two-Hole Straps				Steel		
1/2"	61205B	100/1000	2/20	2.250	1.625	0.562
3/4"	61207B	100/1000	3/30	2.875	2.250	0.638
1"	61210B	50/500	2.5/25	3.375	2.625	0.750
1 1/4"	61212B	25/250	1.75/17.5	4.188	3.437	0.875
1 1/2"	61215B	25/250	3/30	4.625	3.812	0.875
2"	61220B	50/200	7.5/30	5.125	4.250	1.000
2 1/2"	61225B	25	4.3	5.875	4.875	1.000
3"	61230	10	2.5	6.500	5.500	1.000
3 1/2"	61235B	25	6.5	7.375	6.375	1.000
4"	61240B	20	6.6	8.000	7.000	1.000

APPLICATION: INDOORS OR OUTDOORS. Use to secure Rigid or IMC conduit to wood, masonry or similar surfaces where greater load bearing is required. **MATERIAL:** Steel, Zinc Electro-plate.
CERTIFICATIONS: TO UL AND CSA REQUIREMENTS.

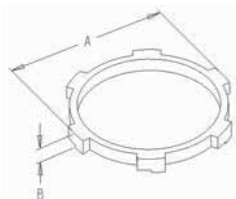

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
Conduit Locknuts			Steel		
1/2"	61905B	200/2000	2/20	1.125	0.09
3/4"	61907B	100/1000	1/10	1.380	0.10
1"	61910B	100/1000	4/40	1.697	0.13
1 1/4"	61912B	50/500	2.5/25	2.070	0.13
1 1/2"	61915B	50/500	3/30	2.385	0.13
2"	61920B	50/200	3.5/14	2.870	0.18
2 1/2"	61925B	25	3.25	3.455	0.18
3"	61930B	25	4.75	4.150	0.18
3 1/2"	61935B	10/40	2.3/9.2	4.703	0.18
4"	61940B	10/40	2.7/10.8	5.288	0.185

APPLICATION: INDOORS OR OUTDOORS. Use to secure Rigid, IMC conduit or various threaded fittings to a steel outlet box or other metal enclosure. **MATERIAL:** Steel with Zinc plating.

