

Part number

CK 03 IA



Brief description:

angled bulkhead housings with single lever, size "21.21", without cable gland, thermoplastic version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

Product description		Approvals / Standards	
Version	thermoplastic version	Quality mark	type: 12,(type 4/4X only with kit CKR 65 or
Series	Angled mounting housings with 1 lever		CKR 65 D),  , EAC
Product type	with 1 lever		CQC, CE
Variant	without cable gland	Conformity	
Style	white colour, RAL 7035	General ordering information	
Family	CK thermoplastic enclosures	EAN13 code	8015747026277
Size	size "21.21"	Tariff number	85369095
Technical data		Packaging Information	
Operating temperature range (min, max)	-40°C ... +125°C	Packaging length	360,00 mm
Material	thermoplastic	Packaging height	170,00 mm
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)	Packaging width	305,00 mm
Further technical details		Packaging weight	1,90 kg
Weight	17,00 g	Packaging volume	18,67 dm³
		Packaging description	Carton box
		Packaging quantity	100 Pcs
		Packaging EAN code	8015747026284
		Sub-packaging length	140,00 mm
		Sub-packaging height	66,00 mm
		Sub-packaging width	150,00 mm
		Sub-packaging weight	0,19 kg
		Sub-packaging volume	1,39 dm³
		Sub-packaging description	Carton Box
		Sub-packaging quantity	10 Pcs
		Sub-packaging EAN barcode	8015747026291

Part number



CK 03 IA



Catalogue drawings

Catalogue drawings

CK IA(N)

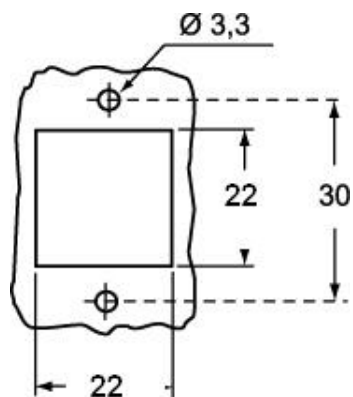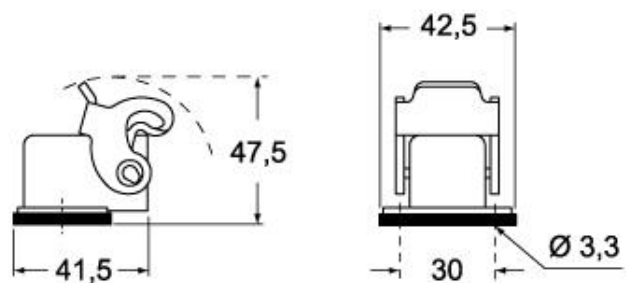

CK IAP(N)S - MK IAP (N)

