


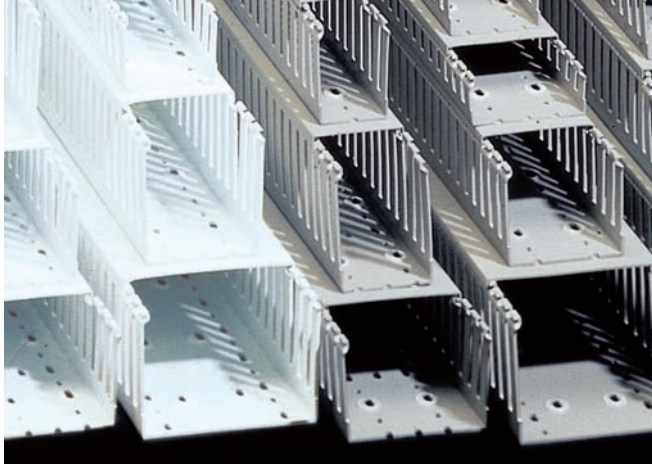

T1

DUCT SERIES

Material

Rigid PVC,
self-extinguishing

Color

Light GREY RAL 7030
WHITE

Standard Length


6 Feet 6 3/4 Inches

Standard Unit

Duct complete
with cover

THE MOST COMPREHENSIVE RANGE

NOMINAL 1 1/2"-2 1/4"-3"-4"

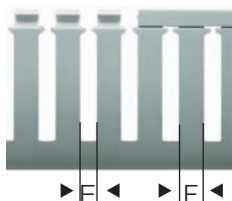

NOMINAL 5/8"-1"



All wiring ducts come complete with cover. Wiring duct covers can be sold separately: see page 8 and IBOCO Corp. Price List.

Catalog Number	Nominal Size (WxH)	Dimensions in inches (Actual)				Dimensions WxH (in millimeters)	Standard Carton (Qty) Lengths (1) Feet	
T1-0506G	1/2 x 5/8	.60	.71	.20	.30	15 x 18	20	120
T1-0510G	1/2 x 1	.60	1.18	.20	.30	15 x 30	20	120
T1-0522G	1/2 x 2 1/4	.60	2.36	.20	.30	15 x 60	16	96
T1-1010*	1 x 1	1.00	1.18	.20	.30	25 x 30	18	108
T1-1015*	1 x 1 1/2	1.00	1.57	.31	.47	25 x 40	18	108
T1-1022*	1 x 2 1/4	1.00	2.36	.31	.47	25 x 60	24	144
T1-1030*	1 x 3	1.00	3.15	.31	.47	25 x 80	24	144
T1-1040*	1 x 4	1.00	3.94	.31	.47	25 x 100	8	48
T1-1515*	1 1/2 x 1 1/2	1.57	1.57	.31	.47	40 x 40	20	120
T1-1522*	1 1/2 x 2 1/4	1.57	2.36	.31	.47	40 x 60	18	108
T1-1530*	1 1/2 x 3	1.57	3.15	.31	.47	40 x 80	16	96
T1-1540*	1 1/2 x 4	1.57	3.94	.31	.47	40 x 100	8	48
T1-2215G	2 1/4 x 1 1/2	2.36	1.57	.31	.47	60 x 40	12	72
T1-2222*	2 1/4 x 2 1/4	2.36	2.36	.31	.47	60 x 60	12	72
T1-2230*	2 1/4 x 3	2.36	3.15	.31	.47	60 x 80	12	72
T1-2240*	2 1/4 x 4	2.36	3.94	.31	.47	60 x 100	4	24
T1-3015G	3 x 1 1/2	3.15	1.57	.31	.47	80 x 40	12	72
T1-3022*	3 x 2 1/4	3.15	2.36	.31	.47	80 x 60	12	72
T1-3030*	3 x 3	3.15	3.15	.31	.47	80 x 80	12	72
T1-3040*	3 x 4	3.15	3.94	.31	.47	80 x 100	4	24
T1-3050*	3 x 5	2.95	4.92	.31	.47	75 x 125	6	36
T1-4015G	4 x 1 1/2	3.94	1.57	.31	.47	100 x 40	8	48
T1-4022G	4 x 2 1/4	3.94	2.36	.31	.47	100 x 60	8	48
T1-4030*	4 x 3	3.94	3.15	.31	.47	100 x 80	8	48
T1-4040*	4 x 4	3.94	3.94	.31	.47	100 x 100	4	24
T1-4050*	4 x 5	3.94	4.92	.31	.47	100 x 125	4	24
T1-6040*	6 x 4	5.91	3.94	.31	.47	150 x 100	4	24


Example: T1-0510 G = 1/2"x 1"light GREY duct with cover

(1) Each standard length is actually 6'6 3/4"
but is counted as 6 feet for packaging and pricing

* Color - add suffix "G" for light GREY "W" for WHITE

ADHESIVE BACKING - add suffix "A" to catalog number - contact sales office for pricing (see page 23)

Available in 1 meter length
contact sales office

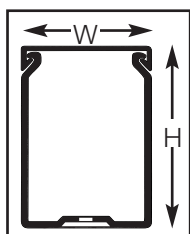

Non-slip cover design of minimum encumbrance and maximum grip.



Restricted slot opening for wire retaining.



Two predetermined breaklines:
- for breaking off and removal of sidewall finger segments only.
- for removal of sidewall finger and base segments.



Burr-free edges.



Recess boss for rapid mounting of components.

For wire fill capacity and base perforation of the wiring duct, see page 18.