


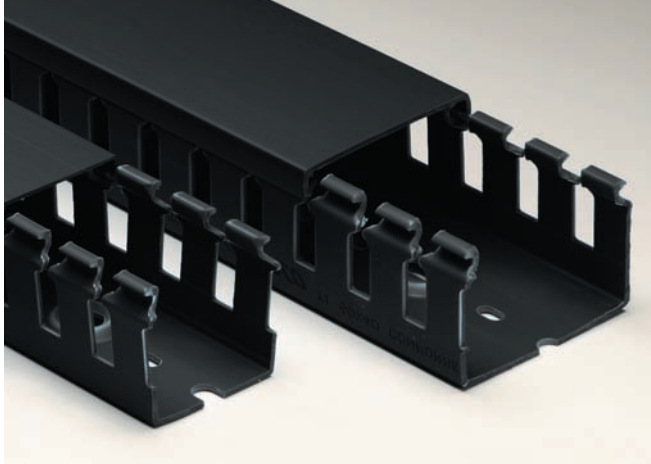

T1-K

DUCT SERIES

Material

Rigid PVC,
self-extinguishing

Color

BLACK


Standard

Length

6 Feet 6 3/4 Inches


Standard Unit

Duct complete
with cover

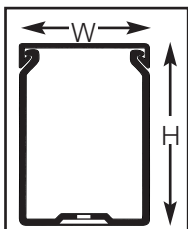

Catalog Number	Nominal Size (WxH)	Dimensions in inches (Actual)					Dimensions WxH (in millimeters)	Standard Carton (Qty)	
		W	H	E	F			Lengths (1)	Feet
T1-1040K	1 x 4	1.00	3.94	.31	.47		25x100	8	48
T1-1530K	1½ x 3	1.57	3.15	.31	.47		40 x 80	16	96
T1-2222K	2¼ x 2¼	2.36	2.36	.31	.47		60 x 60	12	72
T1-2240K	2¼ x 4	2.36	3.94	.31	.47		60x100	4	24
T1-3030K	3 x 3	3.15	3.15	.31	.47		80 x 80	12	72
T1-3040K	3 x 4	3.15	3.94	.31	.47		80x100	4	24
T1-3050K	3 x 5	2.95	4.92	.31	.47		75x125	6	36
T1-4040K	4 x 4	3.94	3.94	.31	.47		100x100	4	24
T1-4050K	4 x 5	3.94	4.92	.31	.47		100x125	4	24

For special sizes contact sales office

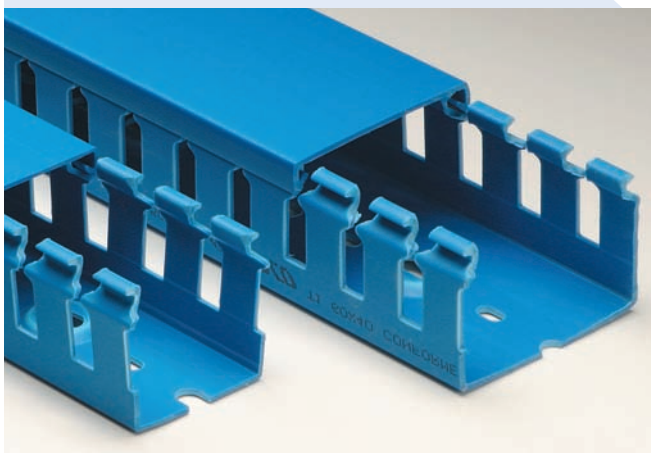

T1-B

Material

Rigid PVC,
self-extinguishing

Color

BLUE RAL 5015


Standard

Length

6 Feet 6 3/4 Inches

Standard Unit

Duct complete
with cover

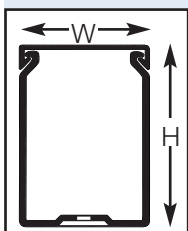

Catalog Number	Nominal Size (WxH)	Dimensions in inches (Actual)					Dimensions WxH (in millimeters)	Standard Carton (Qty)	
		W	H	E	F			Lengths (1)	Feet
T1-1010B	1 x 1	1.00	1.18	.20	.30		25 x 30	18	108
T1-1022B	1 x 2¼	1.00	2.36	.31	.47		25 x 60	24	144
T1-1030B	1 x 3	1.00	3.15	.31	.47		25 x 80	24	144
T1-1515B	1½ x 1½	1.57	1.57	.31	.47		40 x 40	20	120
T1-1522B	1½ x 2¼	1.57	2.36	.31	.47		40 x 60	18	108
T1-1530B	1½ x 3	1.57	3.15	.31	.47		40 x 80	16	96
T1-2215B	2¼ x 1½	2.36	1.57	.31	.47		60 x 40	12	72
T1-2222B	2¼ x 2¼	2.36	2.36	.31	.47		60 x 60	12	72
T1-2230B	2¼ x 3	2.36	3.15	.31	.47		60 x 80	12	72
T1-3030B	3 x 3	3.15	3.15	.31	.47		80 x 80	12	72
T1-3050B	3 x 5	2.95	4.92	.31	.47		75x 125	6	36
T1-4030B	4 x 3	3.94	3.15	.31	.47		100x 80	8	48
T1-4040B	4 x 4	3.94	3.94	.31	.47		100x100	4	24

Blue color duct recognized for intrinsic safe circuits

NOTE : 1) Each standard length is 6' 6¾" but is considered as 6 feet for the purpose of pricing and packaging.