


KEL-DP round Cable Entry Plates




IP65

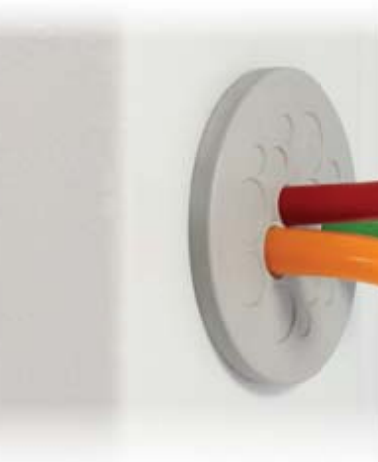

Also available in black.



Membrane on front

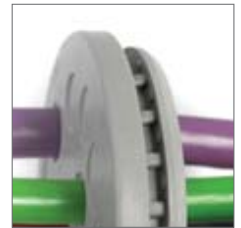

Special fixing ribs ensure a centered fit.

Product Description

KEL-DP entry plates are designed for routing cables without connectors.

The KEL-DP products are a cost saving alternative to traditional cable glands. Ideal for high volume applications where conventional cable glands would normally be used. Simply make a small hole in the thin membrane and push the cables through. The KEL-DP round provides protection IP65 / NEMA Type 12.

ST-B Plugs can be used for sealing pierced membranes if cables have been removed.

A special rib ensures a centered fit in the cut-outs.

Advantages & Benefits

- Fast and easy assembly, no tools required
- High cable density
- Cost-effective
- For wall thickness 1.5 - 4 mm
- Hygienic design - free of dirt-collecting recesses

Type	Order No. Type A	Order No. Type B	Number of cables	Cut-out	External diameter DA	PU
KEL-DP 25 4	☐ 43533 ☒ 50533	-	4× max. 8 mm	ø 25 mm	32 mm	10
KEL-DP 25 6	☐ 43531 ☒ 50531	-	4× max. 5.2 mm 2× max. 9.4 mm	ø 25 mm	32 mm	10
KEL-DP 32 10	☐ 43532 ☒ 50532	☐ 43560 ☒ 50560	6× max. 5.2 mm 2× max. 6.4 mm 2× max. 9.4 mm	ø 32 mm	38 mm	10
NEW KEL-DP 40 9	☐ 43536	☐ 43561	8× max. 9.5 mm 1× max. 11.3 mm	ø 40 mm	50 mm	10
NEW KEL-DP 40 16	☐ 43537	☐ 43563	2× max. 5.3 mm 10× max. 6.3 mm 2× max. 9.5 mm 2× max. 11.3 mm	ø 40 mm	50 mm	10
NEW KEL-DP 40 17	☐ 43538	☐ 43565	1× max. 4 mm 16× max. 7.2 mm	ø 40 mm	50 mm	10

* Only valid for gray product types




IP65

up to
NEMA
TYPE
12


GL

HL3
EN 45545-2UV
ISO 4892-2AECOLAB
certifiedRoHS
compliantMade in
Germanyicotek
NORTH AMERICA

 KEL-DP round Cable Entry Plates



Fastening

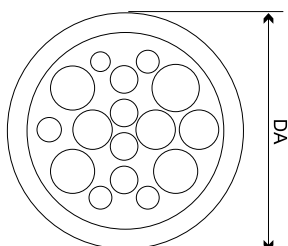

IP65



Type	Order No. Type A	Order No. Type B	Number of cables	Cut-out	External diameter DA	PU
KEL-DP 50 9	43554 50554	43568 50568	5× max. 7 mm 4× max. 18 mm	ø 50 mm	60 mm	10
KEL-DP 50 11	43555 50555	43569 50569	7× max. 7.2 mm 3× max. 11.2 mm 1× max. 22.5 mm	ø 50 mm	60 mm	10
KEL-DP 50 12	43551 50551	43562 50562	10× max. 9.2 mm 2× max. 11.2 mm	ø 50 mm	60 mm	10
KEL-DP 50 16	43550 50550	43564 50564	4× max. 5.3 mm 5× max. 6.3 mm 3× max. 9.5 mm 4× max. 11.3 mm	ø 50 mm	60 mm	10
KEL-DP 50 18	43553 50553	43567 50567	2× max. 4 mm 2× max. 6 mm 4× max. 7.2 mm 5× max. 9.4 mm 5× max. 12 mm	ø 50 mm	60 mm	10
KEL-DP 50 20	43552 50552	43566 50566	16× max. 6.3 mm 4× max. 9.3 mm	ø 50 mm	60 mm	10
KEL-DP 50 35	43556 50556	43570 50570	35× max. 5.2 mm	ø 50 mm	60 mm	10

Specifications

Material	Elastomer
Color	☐ gray (similar RAL 7035) ☒ black
Flame class	UL94-Vo
IP rating	IP65 (certified acc. to EN 60529)
NEMA type rating	NEMA type 12 (acc. to UL 50E)
Temperature	- 40°C to + 90°C (static) - 40°F to + 194°F (static)
Properties	Halogen-free, silicone-free
Cut-out dimensions	Metric sizes
Plate depth	5 mm
Type A:	For wall thickness 1.5 - 2.5 mm
Type B:	For wall thickness 2.8 - 4 mm

Accessories

ST-B Plugs	76
FP Flanged plates	152 - 157

* Only valid for gray product types