

KEL-QTA

Split Cable Entry Plates



IP54



Product Description

The KEL-QTA easily routes pre-terminated cables, multi-conductors, hoses or conduits without using any tools for assembly.

Advantages & Benefits

- Quick assembly without tools
- High cable density by using multi-position grommets
- Simple assembly and disassembly in case of change or service
- Routing of cables with and without connectors in a high density
- Suitable for standard industrial connector cut-outs

 
 
 
 
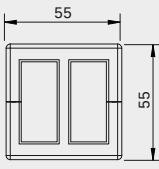
Specifications

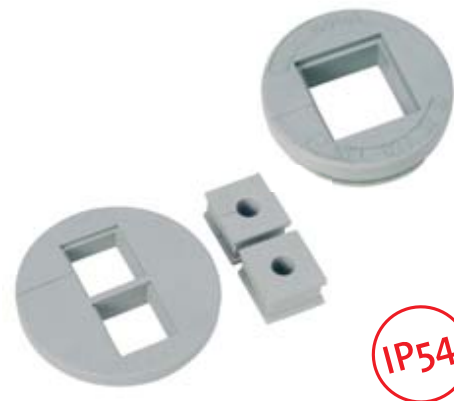
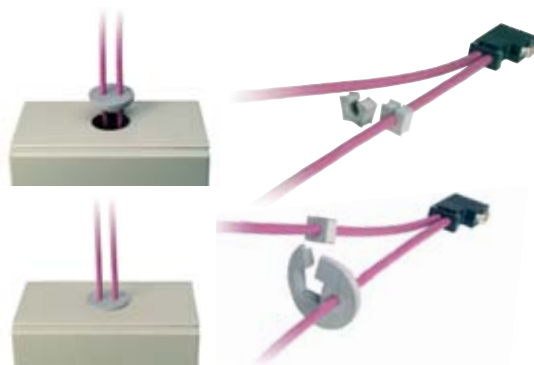
Material	Elastomer
Flame class	UL94-V0
IP Rating	IP54, with correct selection of the cable grommets QT
Temperature	- 40°C to + 90°C (static) - 40°F to + 194°F (static)
Properties	Halogen-free, silicone-free
Frame depth	17 mm

Type A:	For wall thickness 1.5 - 2.5 mm
Type B:	For wall thickness 2.8 - 4 mm

Accessories

QT Cable grommets	56
ST-B Plugs	76
FP Flange plates	152 - 157

Description	Type	Order No. Type A	Order No. Type B	Cut-out [mm]	Cables	PU
	KEL-QTA 24 2 - DP 18	43642	43643	112 × 36	pre-terminated 2× 3 - 15 mm without connector 16× max. 7 mm 1× max. 12 mm 1× max. 16 mm	10
	KEL-QTA 24 4	43644	43645	112 × 36	pre-terminated 4× 3 - 15 mm	10
	KEL-QTA 10 1 - DP 18	43655	43658	65 × 36	pre-terminated 1× 3 - 15 mm without connector 18× max. 5 mm	10
	KEL-QTA 10 2 - DP 6	43656	43659	65 × 36	pre-terminated 2× 3 - 15 mm without connector 6× max. 5 mm	10
	KEL-QTA-B4	43660	-	46 × 46	pre-terminated 4× 3 - 15 mm	



KEL-QTA round | KEL-QTE

Split Cable Entry Plates

Type	Order No. Type A	Order No. Type B	Cut-out [mm]	Cables pre-terminated non-pre-term.	PU	Description
------	---------------------	---------------------	-----------------	--	----	-------------

KEL-QTA 32	43632	43636	Ø 32	1x 3 - 15 mm	-	10	
KEL-QTA 50	43622	43626	Ø 50	2x 3 - 15 mm	-	10	
KEL-QTE 20 2.5	43412	-	Ø 20	1x 2.6 - 3.2 mm	1x max. 5.2 mm	10	
KEL-QTE 20 3	43413	-	Ø 20	1x 3.1 - 3.8 mm	1x max. 5.2 mm	10	
KEL-QTE 20 4	43414	-	Ø 20	1x 3.8 - 4.8 mm	1x max. 5.2 mm	10	
KEL-QTE 20 5	43415	-	Ø 20	1x 4.7 - 5.6 mm	1x max. 5.2 mm	10	

Product Description

The KEL-QTA easily routes pre-terminated cables, multi-conductors, hoses or conduits without using any tools for assembly.

Advantages & Benefits

- Fast and easy assembly without tools
- Increased cable density by using multi-position grommets
- Simple assembly and disassembly in case of change or service
- Routing of cables with and without connectors in a high density

Specifications

Material	Elastomer
Flame class	UL94-Vo
IP Rating (QTA)	IP54, with correct selection of the cable grommets (QT single)
Temperature	- 40°C to + 90°C (static) - 40°F to + 194°F (static)
Properties	Halogen-free, silicone-free
Cut-out dimension	Metric sizes
Type A:	For wall thickness 1.5 - 2.5 mm
Type B:	For wall thickness 2.8 - 4 mm

Accessories

QT Cable grommets 56