


SK

EMC Shield Brackets



Dimensions SK bracket (without mounting foot):

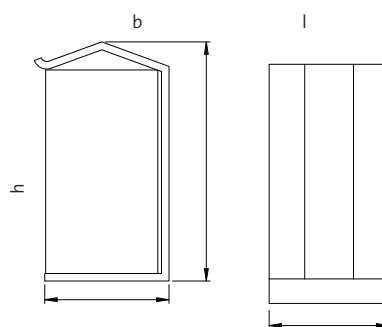

Product Description

SK shield brackets can be used where the shield of single cables has to be grounded.

SK shield brackets can be assembled on a mounting plate with screws, with SC-feet in DIN-rails shape C or with SF-feet on 35 mm DIN-rails shape H.

Advantages & Benefits

- Simple assembly on TS35 DIN rails and 10 x 3 mm bus bars
- Various sizes and possibilities for mounting



SC foot single for C-rail
(PU: 10) Order No. 36220

Specifications

Material
SK-bracket Carbon steel, galvanically zinc plated
SF-foot Spring steel

Accessories

Bus bar 10 x 3 103

Description	Type	Order No.	Shield diameter	Dimensions l x b x h [mm]	PU
For direct mounting (M4-screw included):					
	SK 3-8	36222	3 - 8 mm	18 x 14 x 26	10
	SK 4-13.5	36224	4 - 13.5 mm	20 x 20 x 31	10
	SK 10-20	36226	10 - 20 mm	26 x 24 x 40	10
	SK 15-32	36228	15 - 32 mm	32 x 35 x 64	10
For 35 mm DIN-rail shape H:					
	SF SK 3-8	36500	3 - 8 mm	18 x 14 x 26	10
	SF SK 4-13.5	36502	4 - 13.5 mm	20 x 20 x 31	10
	SF SK 10-20	36504	10 - 20 mm	26 x 24 x 40	10
	SF SK 15-32	36506	15 - 32 mm	32 x 35 x 64	10
For 10 x 3 mm bus bar:					
	SS SK 3-8	36235	3 - 8 mm	18 x 14 x 26	10
	SS SK 4-13.5	36236	4 - 13.5 mm	20 x 20 x 31	10
	SS SK 10-20	36237	10 - 20 mm	26 x 24 x 40	10
	SS SK 15-32	36238	15 - 32 mm	32 x 36 x 64	10
For 35 mm DIN-rail shape C:					
	SC SK 3-8	36696	3 - 8 mm	18 x 14 x 26	10
	SC SK 4-13.5	36700	4 - 13.5 mm	20 x 20 x 31	10
	SC SK 10-20	36704	10 - 20 mm	26 x 24 x 40	10
	SC SK 15-32	36708	15 - 32 mm	32 x 36 x 64	10