



7/8" MIN Series Size I Cordsets

4, 5 & 6 Conductor MIN Series Size I Cordsets, 16AWG

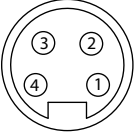
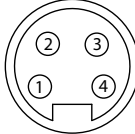
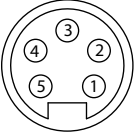
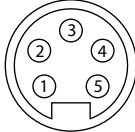
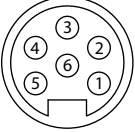
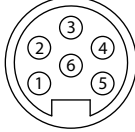


Double Ended Cordsets | 600 Volt, 10 amps | 600 Volt, 8 amps | IP67 Rating



A

MIN Series Size I Cordsets


Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
 7/8"-16UN2	MIN-4MFP-* (YELLOW) MIN-4MFP-*-B (BLACK)	PVC STOOW 4 X 16 AWG 600V, 10A -40°C to +105°C 10.8mm OD	Industry Standard PVC	North American 1. Black 2. White 3. Red 4. Green/Yellow	 7/8"-16UN2
	MINM-4MFP-*	Yellow PVC STOW With Foil Shield 4 X 16 AWG 600V, 10A -40°C to +105°C 10.8mm OD	Industry Standard PVC Foil Shield		
 7/8"-16UN2	MIN-5MFP-* (YELLOW) MIN-5MFP-*-B (BLACK)	Yellow PVC STOOW 5 X 16 AWG 600V, 8A -40°C to +105°C 13.1mm OD	Industry Standard PVC	North American 1. White 2. Red 3. Green/Yellow 4. Orange 5. Black	 7/8"-16UN2
	MINM-5MFP-*	Yellow PVC STOOW With Foil Shield 5 X 16 AWG 600V, 8A -40°C to +105°C 13.1mm OD	Industry Standard PVC		
	MINW-5MFP-*	TPE SEOOW 5 X 16 AWG 600V, 8A -40°C to +80°C 13.1mm OD	Weld Slag Resistant TPE		
 7/8"-16UN2	MIN-6MFP-* (YELLOW) MIN-6MFP-*-B (BLACK)	PVC STOOW 6 X 16 AWG 600V, 8A -40°C to +105°C 13.3mm OD	Industry Standard PVC	North American 1. White 2. Red 3. Green/Yellow 4. Orange 5. Black 6. Blue	 7/8"-16UN2

* Lengths in feet. Standard cable lengths are 3, 6, 12, 20, 30 & 50 feet. Consult factory for other lengths.


Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "SS" suffix. (e.g. MIN-4MFP-3 becomes MIN-4MFP-3-SS)

For male threaded coupling replace "MFP" with "MFPM". (e.g. MIN-5MFP-3 becomes MIN-5MFPM-3)

 See Page A-33 for Armored Cordset options.



Male - Female Extension

 

Male (Male Threads) - Female (Female Threads) Extension