


KLR Series Three Phase Reactors

480 V - 3% Z 240 V - 6% Z 575 V - 2.4% Z	Part Number	NEC Motor HP			Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed
		480V	575V	240V				Height x Width x Depth	Wgt	
	KLR2ATB	1	1	-	2	8	TB	4.00 x 4.25 x 3.00	3	KLR2ATB1
	KLR3ATB	1.5	1.5-2	.5	3	9	TB	4.00 x 4.25 x 3.00	3	KLR3ATB1
	KLR4ATB	2	3	.75	4	15	TB	4.00 x 4.25 x 3.00	4	KLR4ATB1
	KLR6ATB	3	3	1-1.5	6	17	TB	4.00 x 4.25 x 3.00	3	KLR6ATB1
	KLR8ATB	5	5	2	8	27	TB	4.00 x 5.00 x 4.00	3	KLR8ATB1
	KLR12ATB	7.5	7.5-10	3	12	31	TB	5.00 x 7.00 x 5.00	7	KLR12ATB1
	KLR16ATB	10	10	5	16	38	TB	5.75 x 6.00 x 4.00	8	KLR16ATB1
	KLR18ATB	12	15	5	18	40	TB	5.75 x 8.00 x 5.00	11	KLR18ATB2
	KLR21ATB	15	15	5	21	45	TB	5.75 x 8.00 x 5.00	11	KLR21ATB2
	KLR25ATB	15	20	7.5	25	48	TB	5.75 x 8.00 x 5.00	11	KLR25ATB2
	KLR27ATB	20	25	7.5	27	58	TB	5.75 x 8.00 x 5.00	11	KLR27ATB2
	KLR35ATB	20-25	30	10	35	70	TB	5.75 x 8.00 x 5.00	14	KLR35ATB2
	KLR45ATB	30	40	15	45	74	TB	5.75 x 8.00 x 5.00	14	KLR45ATB2
	KLR55ATB	40	50	20	55	113	TB	7.00 x 9.00 x 6.00	22	KLR55ATB3
	KLR80ATB	50-60	60-75	25-30	80	129	TB	9.00 x 11.00 x 6.00	31	KLR80ATB4
	KLR110ACB	75	100	40	110	152	CB	9.00 x 11.00 x 7.00	49	KLR110ACB4
	KLR130ACB	100	125	50	130	148	CB	9.00 x 11.00 x 8.00	50	KLR130ACB4
	KLR160ACB	125	150	60	160	165	CB	9.00 x 11.00 x 8.00	53	KLR160ACB4
	KLR200ACB	150	200	75	200	222	CB	11.38 x 14.00 x 8.00	81	KLR200ACB5
	KLR250ACB	200	250	100	250	261	CB	11.38 x 14.00 x 8.00	91	KLR250ACB5
	KLR300ACB	250	300	100	300	291	CB	11.38 x 14.00 x 8.00	101	KLR300ACB5
	KLR360ACB	300	350	125-150	360	380	CB	11.38 x 14.00 x 8.00	98	KLR360ACB5
	KLR420ACB	350	400-450	150	420	400	CB	11.38 x 14.00 x 8.00	100	KLR420ACB5
	KLR480ACB	400	500	200	480	392	CB	11.38 x 15.00 x 11.00	110	KLR480ACB5
	KLR600ACB	450	625	250	600	493	CB	11.38 x 15.00 x 13.00	150	KLR600ACB5
	KLR750ACB	500	720	300	750	515	CB	17.25 x 16.94 x 10.25	276	KLR750ACB7
KLR850ACB	750	800	350	850	569	CB	17.25 x 16.94 x 10.25	290	KLR850ACB7	
KLR950ACB	800	975	390	950	686	CB	17.25 x 16.94 x 10.25	295	KLR950ACB7	


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

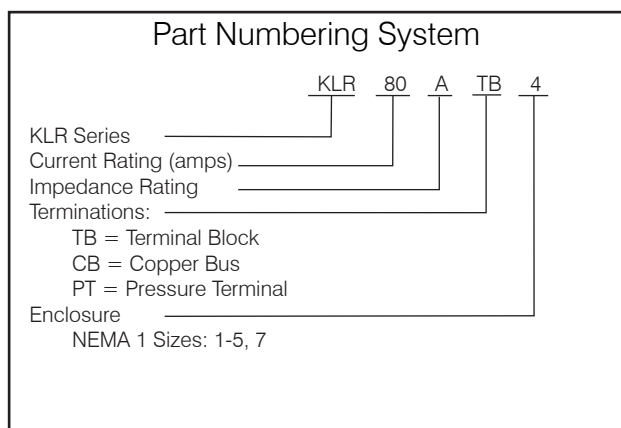

KLR Series Three Phase Reactors

	Part Number	NEC Motor HP			Rated Amps	Watts Loss	UL Type 1 Enclosed		UL Type 3R Enclosed	
		480V	575V	240V			Part Number *		Part Number *	
480 V - 3% Z 240 V - 6% Z	KLRUL2ATB	1	1	-	2	8	KLRUL2ATBE01		KLRUL2ATBE3R	
	KLRUL3ATB	1.5	1.5-2	.5	3	9	KLRUL3ATBE01		KLRUL3ATBE3R	
	KLRUL4ATB	2	3	.75	4	15	KLRUL4ATBE01		KLRUL4ATBE3R	
	KLRUL6ATB	3	3	1-1.5	6	17	KLRUL6ATBE01		KLRUL6ATBE3R	
	KLRUL8ATB	5	5	2	8	27	KLRUL8ATBE01		KLRUL8ATBE3R	
	KLRUL12ATB	7.5	7.5-10	3	12	31	KLRUL12ATBE01		KLRUL12ATBE3R	
	KLRUL16ATB	10	10	5	16	38	KLRUL16ATBE01		KLRUL16ATBE3R	
	KLRUL18ATB	12	15	5	18	40	KLRUL18ATBE01		KLRUL18ATBE3R	
	KLRUL21ATB	15	15	5	21	45	KLRUL21ATBE01		KLRUL21ATBE3R	
	KLRUL25ATB	15	20	7.5	25	48	KLRUL25ATBE01		KLRUL25ATBE3R	
	KLRUL27ATB	20	25	7.5	27	58	KLRUL27ATBE01		KLRUL27ATBE3R	
	KLRUL35ATB	20-25	30	10	35	70	KLRUL35ATBE01		KLRUL35ATBE3R	
	KLRUL45ATB	30	40	15	45	74	KLRUL45ATBE01		KLRUL45ATBE3R	
	KLRUL55ATB	40	50	20	55	113	KLRUL55ATBE01		KLRUL55ATBE3R	
	KLRUL80ATB	50-60	60-75	25-30	80	129	KLRUL80ATBE01		KLRUL80ATBE3R	
	KLRUL110APT	75	100	40	110	152	KLRUL110APTE01		KLRUL110APTE3R	
	KLRUL130APT	100	125	50	130	148	KLRUL130APTE01		KLRUL130APTE3R	
	KLRUL160APT	125	150	60	160	165	KLRUL160APTE01		KLRUL160APTE3R	
	KLRUL200APT	150	200	75	200	222	KLRUL200APTE01		KLRUL200APTE3R	
	KLRUL250APT	200	250	100	250	261	KLRUL250APTE01		KLRUL250APTE3R	
	KLRUL300APT	250	300	100	300	291	KLRUL300APTE01		KLRUL300APTE3R	
	KLRUL360APT	300	350	125-150	360	380	KLRUL360APTE01		KLRUL360APTE3R	
	KLRUL420APT	350	400-450	150	420	400	KLRUL420APTE01		KLRUL420APTE3R	
	KLRUL480APT	400	500	200	480	392	KLRUL480APTE01		KLRUL480APTE3R	
	KLRUL600APT	450	625	250	600	493	KLRUL600APTE01		KLRUL600APTE3R	
	KLRUL750APT	500	720	300	750	515	KLRUL750APTE01			
	KLRUL850APT	750	800	350	850	569	KLRUL850APTE01			
	KLRUL950APT	800	975	390	950	686	KLRUL950APTE01			


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

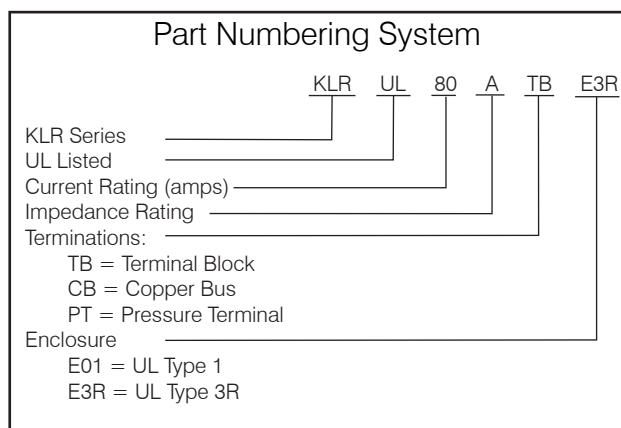

KLR Series Three Phase Reactors

Part Number	NEC Motor HP		Rated	Watts	Stand.	Dimensions (in.)		NEMA 1 Enclosed
	480V	240V	Amps	Loss	Terms	Height x Width x Depth	Wgt	
KLR2BTB	1	-	2	4	TB	4.00 x 5.00 x 4.00	3	KLR2BTB1
KLR3BTB	1.5	0.5	3	5	TB	4.00 x 5.00 x 4.00	3	KLR3BTB1
KLR4BTB	2	0.75	4	9	TB	4.00 x 5.00 x 4.00	3	KLR4BTB1
KLR6BTB	3	1-1.5	6	9	TB	4.00 x 5.00 x 4.00	3	KLR6BTB1
KLR8BTB	5	2	8	14	TB	4.00 x 5.00 x 4.00	3	KLR8BTB1
KLR12BTB	7.5	3	12	20	TB	4.00 x 5.00 x 4.00	3	KLR12BTB1
KLR16BTB	10	5	16	20	TB	5.00 x 6.00 x 4.00	7	KLR16BTB1
KLR18BTB	12	5	18	27	TB	6.00 x 7.00 x 4.00	8	KLR18BTB2
KLR21BTB	15	5	21	30	TB	6.00 x 7.00 x 4.00	8	KLR21BTB2
KLR25BTB	15	7.5	25	36	TB	6.00 x 7.00 x 4.00	8	KLR25BTB2
KLR27BTB	20	7.5	27	43	TB	6.00 x 7.00 x 4.00	8	KLR27BTB2
KLR35BTB	20 - 25	10	35	55	TB	6.00 x 7.00 x 4.00	8	KLR35BTB2
KLR45BTB	30	15	45	59	TB	6.00 x 7.00 x 4.00	8	KLR45BTB2
KLR55BTB	40	20	55	70	TB	5.75 x 8.00 x 5.00	11	KLR55BTB2
KLR80BTB	50 - 60	25-30	80	105	TB	7.00 x 9.00 x 6.00	22	KLR80BTB3
KLR110BCB	75	40	110	95	CB	7.00 x 10.00 x 7.00	26	KLR110BCB4
KLR130BCB	100	50	130	117	CB	9.00 x 11.00 x 7.00	33	KLR130BCB4
KLR160BCB	125	60	160	127	CB	9.00 x 11.00 x 7.00	47	KLR160BCB4
KLR200BCB	150	75	200	135	CB	9.00 x 11.00 x 7.00	42	KLR200BCB4
KLR250BCB	200	100	250	161	CB	9.00 x 11.00 x 7.00	48	KLR250BCB4
KLR300BCB	250	100	300	216	CB	9.00 x 11.00 x 9.00	54	KLR300BCB5
KLR360BCB	300	125-150	360	221	CB	9.00 x 11.00 x 9.00	65	KLR360BCB5
KLR420BCB	350	150	420	275	CB	11.38 x 14.00 x 8.00	85	KLR420BCB5
KLR480BCB	400	200	480	267	CB	11.38 x 14.00 x 8.00	90	KLR480BCB5
KLR600BCB	450	250	600	338	CB	11.38 x 14.00 x 8.00	96	KLR600BCB5
KLR750BCB	500	300	750	372	CB	12.38 x 13.44 x 10.25	147	KLR750BCB7
KLR850BCB	750	350	850	389	CB	12.38 x 13.44 x 10.25	156	KLR850BCB7
KLR950BCB	800	390	950	479	CB	12.38 x 13.44 x 10.25	160	KLR950BCB7


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

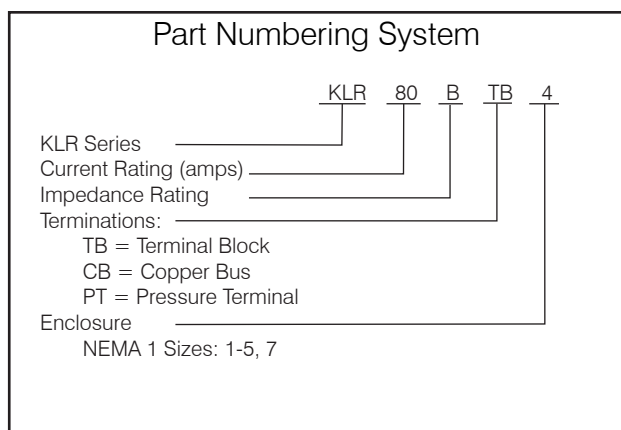

KLR Series Three Phase Reactors

480 V - 1.5% Z 3% Z 240 V -	Part Number	NEC Motor HP		Rated Amps	Watts Loss	UL Type 1 Enclosed		UL Type 3R Enclosed	
		480V	240V			Part Number *		Part Number *	
	KLRUL2BTB	1	-	2	4	KLRUL2BTBE01		KLRUL2BTBE3R	
	KLRUL3BTB	1.5	0.5	3	5	KLRUL3BTBE01		KLRUL3BTBE3R	
	KLRUL4BTB	2	0.75	4	9	KLRUL4BTBE01		KLRUL4BTBE3R	
	KLRUL6BTB	3	1-1.5	6	9	KLRUL6BTBE01		KLRUL6BTBE3R	
	KLRUL8BTB	5	2	8	14	KLRUL8BTBE01		KLRUL8BTBE3R	
	KLRUL12BTB	7.5	3	12	20	KLRUL12BTBE01		KLRUL12BTBE3R	
	KLRUL16BTB	10	5	16	20	KLRUL16BTBE01		KLRUL16BTBE3R	
	KLRUL18BTB	12	5	18	27	KLRUL18BTBE01		KLRUL18BTBE3R	
	KLRUL21BTB	15	5	21	30	KLRUL21BTBE01		KLRUL21BTBE3R	
	KLRUL25BTB	15	7.5	25	36	KLRUL25BTBE01		KLRUL25BTBE3R	
	KLRUL27BTB	20	7.5	27	43	KLRUL27BTBE01		KLRUL27BTBE3R	
	KLRUL35BTB	20 - 25	10	35	55	KLRUL35BTBE01		KLRUL35BTBE3R	
	KLRUL45BTB	30	15	45	59	KLRUL45BTBE01		KLRUL45BTBE3R	
	KLRUL55BTB	40	20	55	70	KLRUL55BTBE01		KLRUL55BTBE3R	
	KLRUL80BTB	50 - 60	25-30	80	105	KLRUL80BTBE01		KLRUL80BTBE3R	
	KLRUL110BPT	75	40	110	95	KLRUL110BPTE01		KLRUL110BPTE3R	
	KLRUL130BPT	100	50	130	117	KLRUL130BPTE01		KLRUL130BPTE3R	
	KLRUL160BPT	125	60	160	127	KLRUL160BPTE01		KLRUL160BPTE3R	
	KLRUL200BPT	150	75	200	135	KLRUL200BPTE01		KLRUL200BPTE3R	
	KLRUL250BPT	200	100	250	161	KLRUL250BPTE01		KLRUL250BPTE3R	
	KLRUL300BPT	250	100	300	216	KLRUL300BPTE01		KLRUL300BPTE3R	
	KLRUL360BPT	300	125-150	360	221	KLRUL360BPTE01		KLRUL360BPTE3R	
	KLRUL420BPT	350	150	420	275	KLRUL420BPTE01		KLRUL420BPTE3R	
	KLRUL480BPT	400	200	480	267	KLRUL480BPTE01		KLRUL480BPTE3R	
	KLRUL600BPT	450	250	600	338	KLRUL600BPTE01		KLRUL600BPTE3R	
	KLRUL750BPT	500	300	750	372	KLRUL750BPTE01			
	KLRUL850BPT	750	350	850	389	KLRUL850BPTE01			
	KLRUL950BPT	800	390	950	479	KLRUL950BPTE01			


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

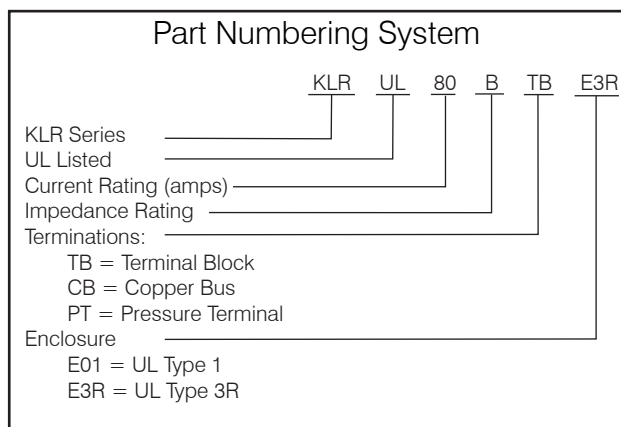

KLR Series Three Phase Reactors

480 Volt 5% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed	
						Height x Width x Depth	Wgt	Part Number *	
	KLR2CTB	1	2	11	TB	4.00 x 5.00 x 4.00	3	KLR2CTB1	
	KLR3CTB	1.5	3	14	TB	4.00 x 5.00 x 4.00	3	KLR3CTB1	
	KLR4CTB	2	4	23	TB	4.00 x 5.00 x 4.00	3	KLR4CTB1	
	KLR6CTB	3	6	22	TB	5.00 x 7.00 x 5.00	7	KLR6CTB1	
	KLR8CTB	5	8	34	TB	5.00 x 7.00 x 5.00	7	KLR8CTB1	
	KLR12CTB	7.5	12	54	TB	5.00 x 7.00 x 5.00	8	KLR12CTB1	
	KLR16CTB	10	16	58	TB	5.75 x 8.00 x 5.00	12	KLR16CTB2	
	KLR18CTB	12	18	75	TB	5.75 x 8.00 x 5.00	12	KLR18CTB2	
	KLR21CTB	15	21	59	TB	5.75 x 8.00 x 5.00	14	KLR21CTB2	
	KLR25CTB	15	25	67	TB	5.75 x 8.00 x 5.00	14	KLR25CTB2	
	KLR27CTB	20	27	80	TB	5.75 x 8.00 x 5.00	14	KLR27CTB2	
	KLR35CTB	20 - 25	35	97	TB	7.00 x 9.00 x 6.00	22	KLR35CTB3	
	KLR45CTB	30	45	118	TB	7.00 x 9.00 x 6.00	24	KLR45CTB3	
	KLR55CTB	40	55	150	TB	9.00 x 11.00 x 6.00	32	KLR55CTB4	
	KLR80CTB	50 - 60	80	154	TB	9.00 x 11.00 x 7.00	49	KLR80CTB4	
	KLR110CCB	75	110	191	CB	9.00 x 11.00 x 8.00	53	KLR110CCB4	
	KLR130CCB	100	130	239	CB	11.38 x 14.00 x 8.00	82	KLR130CCB5	
	KLR160CCB	125	160	254	CB	11.38 x 14.00 x 8.00	89	KLR160CCB5	
	KLR200CCB	150	200	337	CB	11.38 x 14.00 x 8.00	110	KLR200CCB5	
	KLR250CCB	200	250	353	CB	11.38 x 14.00 x 10.00	115	KLR250CCB5	
	KLR300CCB	250	300	443	CB	11.38 x 15.00 x 11.00	122	KLR300CCB5	
	KLR360CCB	300	360	406	CB	11.38 x 15.00 x 11.00	156	KLR360CCB5	
	KLR420CCB	350	420	500	CB	11.38 x 15.00 x 13.00	170	KLR420CCB5	
	KLR480CCB	400	480	522	CB	11.38 x 15.00 x 13.00	175	KLR480CCB5	
	KLR600CCB	450	600	650	CB	17.25 x 16.94 x 10.25	275	KLR600CCB7	
	KLR750CCB	500	750	732	CB	17.25 x 16.94 x 10.25	260	KLR750CCB7	
	KLR850CCB	750	850	850	CB	17.25 x 16.94 x 10.25	280	KLR850CCB7	
	KLR950CCB	800	950	978	CB	17.25 x 16.94 x 10.25	290	KLR950CCB7	


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

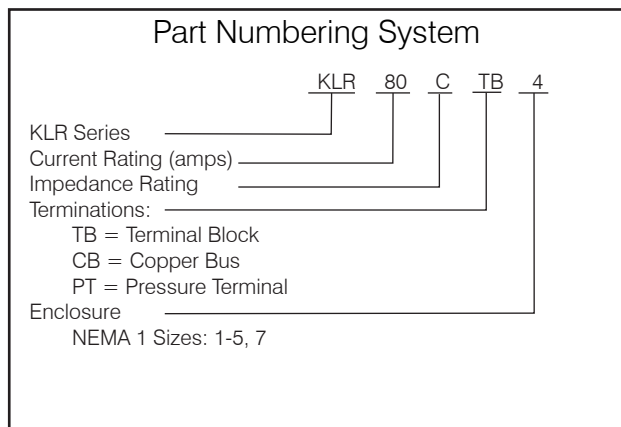

KLR Series Three Phase Reactors

480 Volt 5% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	UL Type 1 Enclosed		UL Type 3R Enclosed	
	Part Number *				Part Number *		Part Number *	
	KLRUL2CTB	1	2	11	KLRUL2CTBE01		KLRUL2CTBE3R	
	KLRUL3CTB	1.5	3	14	KLRUL3CTBE01		KLRUL3CTBE3R	
	KLRUL4CTB	2	4	23	KLRUL4CTBE01		KLRUL4CTBE3R	
	KLRUL6CTB	3	6	22	KLRUL6CTBE01		KLRUL6CTBE3R	
	KLRUL8CTB	5	8	34	KLRUL8CTBE01		KLRUL8CTBE3R	
	KLRUL12CTB	7.5	12	54	KLRUL12CTBE01		KLRUL12CTBE3R	
	KLRUL16CTB	10	16	58	KLRUL16CTBE01		KLRUL16CTBE3R	
	KLRUL18CTB	12	18	75	KLRUL18CTBE01		KLRUL18CTBE3R	
	KLRUL21CTB	15	21	59	KLRUL21CTBE01		KLRUL21CTBE3R	
	KLRUL25CTB	15	25	67	KLRUL25CTBE01		KLRUL25CTBE3R	
	KLRUL27CTB	20	27	80	KLRUL27CTBE01		KLRUL27CTBE3R	
	KLRUL35CTB	20 - 25	35	97	KLRUL35CTBE01		KLRUL35CTBE3R	
	KLRUL45CTB	30	45	118	KLRUL45CTBE01		KLRUL45CTBE3R	
	KLRUL55CTB	40	55	150	KLRUL55CTBE01		KLRUL55CTBE3R	
	KLRUL80CTB	50 - 60	80	154	KLRUL80CTBE01		KLRUL80CTBE3R	
	KLRUL110CPT	75	110	191	KLRUL110CPTE01		KLRUL110CPTE3R	
	KLRUL130CPT	100	130	239	KLRUL130CPTE01		KLRUL130CPTE3R	
	KLRUL160CPT	125	160	254	KLRUL160CPTE01		KLRUL160CPTE3R	
	KLRUL200CPT	150	200	337	KLRUL200CPTE01		KLRUL200CPTE3R	
	KLRUL250CPT	200	250	353	KLRUL250CPTE01		KLRUL250CPTE3R	
	KLRUL300CPT	250	300	443	KLRUL300CPTE01		KLRUL300CPTE3R	
	KLRUL360CPT	300	360	406	KLRUL360CPTE01		KLRUL360CPTE3R	
	KLRUL420CPT	350	420	500	KLRUL420CPTE01		KLRUL420CPTE3R	
	KLRUL480CPT	400	480	522	KLRUL480CPTE01		KLRUL480CPTE3R	
	KLRUL600CPT	450	600	650	KLRUL600CPTE01		KLRUL600CPTE3R	
	KLRUL750CPT	500	750	732	KLRUL750CPTE01			
	KLRUL850CPT	750	850	850	KLRUL850CPTE01			
	KLRUL950CPT	800	950	978	KLRUL950CPTE01			


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

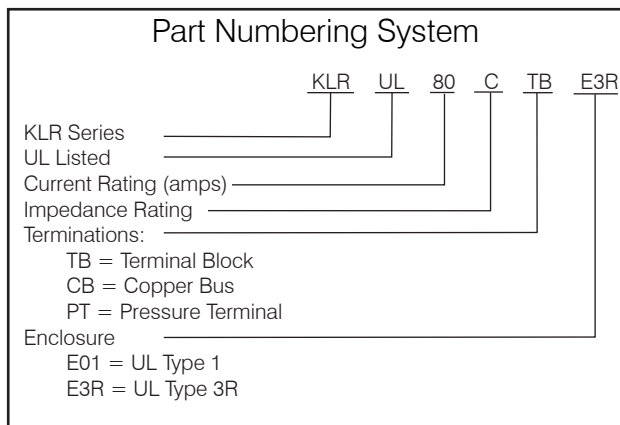

KLR Series Three Phase Reactors

575 Volt 3% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed	
						Height x Width x Depth	Wgt	Part Number *	
	KLR2DTB	1	2	9	TB	4.00 x 5.00 x 4.00	4	KLR2DTB1	
	KLR3DTB	1.5 - 2	3	12	TB	4.00 x 5.00 x 4.00	4	KLR3DTB1	
	KLR4DTB	3	4	18	TB	4.00 x 4.25 x 3.00	4	KLR4DTB1	
	KLR6DTB	3	6	22	TB	4.00 x 5.00 x 4.00	5	KLR6DTB1	
	KLR8DTB	5	8	28	TB	5.00 x 7.00 x 5.00	7	KLR8DTB1	
	KLR12DTB	7.5	12	44	TB	5.00 x 7.00 x 5.00	7	KLR12DTB1	
	KLR16DTB	10	16	52	TB	5.00 x 6.00 x 4.00	8	KLR16DTB1	
	KLR18DTB	15	18	44	TB	5.75 x 8.00 x 5.00	12	KLR18DTB2	
	KLR21DTB	15	21	51	TB	5.75 x 8.00 x 5.00	13	KLR21DTB2	
	KLR25DTB	20	25	72	TB	5.75 x 8.00 x 5.00	13	KLR25DTB2	
	KLR27DTB	25	27	62	TB	5.75 x 8.00 x 5.00	13	KLR27DTB2	
	KLR35DTB	30	35	79	TB	5.75 x 8.00 x 5.00	16	KLR35DTB2	
	KLR45DTB	40	45	90	TB	7.00 x 9.00 x 6.00	26	KLR45DTB3	
	KLR55DTB	50	55	90	TB	7.00 x 9.00 x 6.00	24	KLR55DTB3	
	KLR80DTB	60 - 75	80	116	TB	9.00 x 11.00 x 7.00	49	KLR80DTB4	
	KLR110DCB	100	110	217	CB	9.50 x 10.56 x 8.25	47	KLR110DCB4	
	KLR130DCB	125	130	242	CB	9.50 x 10.56 x 8.25	47	KLR130DCB4	
	KLR160DCB	150	160	261	CB	9.00 x 11.00 x 7.00	47	KLR160DCB4	
	KLR200DCB	200	200	270	CB	12.38 x 13.44 x 9.00	81	KLR200DCB5	
	KLR250DCB	250	250	316	CB	12.38 x 13.44 x 9.00	91	KLR250DCB5	
	KLR300DCB	300	300	335	CB	12.38 x 13.44 x 9.00	101	KLR300DCB5	
	KLR360DCB	350	360	420	CB	12.38 x 13.44 x 9.00	98	KLR360DCB5	
	KLR420DCB	400	420	435	CB	12.38 x 13.44 x 9.00	100	KLR420DCB5	
	KLR480DCB	500	480	395	CB	12.38 x 13.44 x 10.25	175	KLR480DCB5	
	KLR600DCB	600	600	580	CB	12.38 x 13.44 x 10.25	150	KLR600DCB5	
	KLR750DCB	700	750	604	CB	18.00 x 18.00 x 13.00	270	KLR750DCB7	
	KLR850DCB	800	850	703	CB	18.00 x 18.00 x 12.00	275	KLR850DCB7	
	KLR950DCB	900	950	773	CB	18.00 x 18.00 x 12.00	280	KLR950DCB7	


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

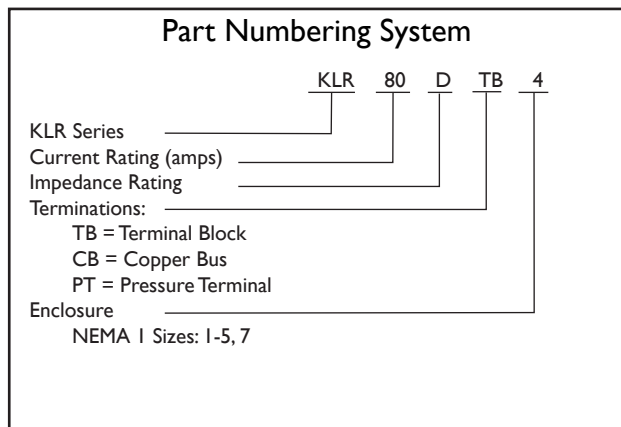

KLR Series Three Phase Reactors

575 Volt 3% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	UL Type 1 Enclosed		UL Type 3R Enclosed	
					Part Number *		Part Number *	
	KLRUL2DTB	1	2	9	KLRUL2DTBE01		KLRUL2DTBE3R	
	KLRUL3DTB	1.5 - 2	3	12	KLRUL3DTBE01		KLRUL3DTBE3R	
	KLRUL4DTB	3	4	18	KLRUL4DTBE01		KLRUL4DTBE3R	
	KLRUL6DTB	3	6	22	KLRUL6DTBE01		KLRUL6DTBE3R	
	KLRUL8DTB	5	8	28	KLRUL8DTBE01		KLRUL8DTBE3R	
	KLRUL12DTB	7.5	12	44	KLRUL12DTBE01		KLRUL12DTBE3R	
	KLRUL16DTB	10	16	52	KLRUL16DTBE01		KLRUL16DTBE3R	
	KLRUL18DTB	15	18	44	KLRUL18DTBE01		KLRUL18DTBE3R	
	KLRUL21DTB	15	21	51	KLRUL21DTBE01		KLRUL21DTBE3R	
	KLRUL25DTB	20	25	72	KLRUL25DTBE01		KLRUL25DTBE3R	
	KLRUL27DTB	25	27	62	KLRUL27DTBE01		KLRUL27DTBE3R	
	KLRUL35DTB	30	35	79	KLRUL35DTBE01		KLRUL35DTBE3R	
	KLRUL45DTB	40	45	90	KLRUL45DTBE01		KLRUL45DTBE3R	
	KLRUL55DTB	50	55	90	KLRUL55DTBE01		KLRUL55DTBE3R	
	KLRUL80DTB	60 - 75	80	116	KLRUL80DTBE01		KLRUL80DTBE3R	
	KLRUL110DPT	100	110	217	KLRUL110DPTE01		KLRUL110DPTE3R	
	KLRUL130DPT	125	130	242	KLRUL130DPTE01		KLRUL130DPTE3R	
	KLRUL160DPT	150	160	261	KLRUL160DPTE01		KLRUL160DPTE3R	
	KLRUL200DPT	200	200	270	KLRUL200DPTE01		KLRUL200DPTE3R	
	KLRUL250DPT	250	250	316	KLRUL250DPTE01		KLRUL250DPTE3R	
	KLRUL300DPT	300	300	335	KLRUL300DPTE01		KLRUL300DPTE3R	
	KLRUL360DPT	350	360	420	KLRUL360DPTE01		KLRUL360DPTE3R	
	KLRUL420DPT	400	420	435	KLRUL420DPTE01		KLRUL420DPTE3R	
	KLRUL480DPT	500	480	395	KLRUL480DPTE01		KLRUL480DPTE3R	
	KLRUL600DPT	600	600	580	KLRUL600DPTE01		KLRUL600DPTE3R	
	KLRUL750DPT	700	750	604	KLRUL750DPTE01			
	KLRUL850DPT	800	850	703	KLRUL850DPTE01			
	KLRUL950DPT	900	950	773	KLRUL950DPTE01			


Part Numbering System

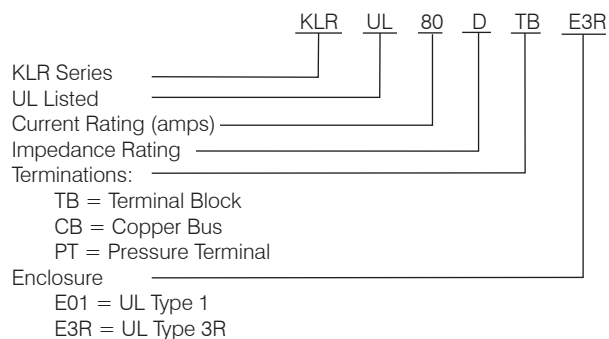

KLR Series Three Phase Reactors

575 Volt 5% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed
						Height x Width x Depth	Wgt	Part Number *
	KLR2ETB	1	2	13	TB	4.00 x 5.00 x 4.00	4	KLR2ETB1
	KLR3ETB	1.5 - 2	3	17	TB	4.00 x 5.00 x 4.00	5	KLR3ETB1
	KLR4ETB	3	4	27	TB	4.00 x 5.00 x 4.00	5	KLR4ETB1
	KLR6ETB	3	6	28	TB	5.00 x 7.00 x 5.00	7	KLR6ETB1
	KLR8ETB	5	8	48	TB	5.00 x 7.00 x 5.00	7	KLR8ETB1
	KLR12ETB	7.5	12	56	TB	5.75 x 8.00 x 5.00	8	KLR12ETB2
	KLR16ETB	10	16	67	TB	5.75 x 8.00 x 5.00	13	KLR16ETB2
	KLR18ETB	15	18	73	TB	5.60 x 6.94 x 3.44	12	KLR18ETB2
	KLR21ETB	15	21	69	TB	5.75 x 8.00 x 5.00	17	KLR21ETB2
	KLR25ETB	20	25	92	TB	7.00 x 9.00 x 6.00	17	KLR25ETB3
	KLR27ETB	25	27	94	TB	7.00 x 9.00 x 6.00	17	KLR27ETB3
	KLR35ETB	30	35	125	TB	7.00 x 9.00 x 6.00	23	KLR35ETB3
	KLR45ETB	40	45	146	TB	7.00 x 9.00 x 7.00	26	KLR45ETB4
	KLR55ETB	50	55	132	TB	7.00 x 10.00 x 7.00	49	KLR55ETB4
	KLR80ETB	60 - 75	80	178	TB	9.00 x 11.00 x 7.00	49	KLR80ETB4
	KLR110ECB	100	110	259	CB	8.50 x 14.00 x 8.00	82	KLR110ECB5
	KLR130ECB	125	130	287	CB	11.38 x 14.00 x 8.00	82	KLR130ECB5
	KLR160ECB	150	160	299	CB	11.38 x 14.00 x 8.00	89	KLR160ECB5
	KLR200ECB	200	200	349	CB	11.38 x 14.00 x 9.00	110	KLR200ECB5
	KLR250ECB	250	250	375	CB	11.38 x 14.00 x 9.00	115	KLR250ECB5
	KLR300ECB	300	300	422	CB	11.38 x 15.00 x 11.00	156	KLR300ECB5
	KLR360ECB	350	360	463	CB	11.38 x 15.00 x 11.00	160	KLR360ECB5
	KLR420ECB	400	420	532	CB	11.38 x 15.00 x 11.00	170	KLR420ECB5
	KLR480ECB	500	480	576	CB	11.38 x 15.00 x 11.00	175	KLR480ECB5
	KLR600ECB	600	600	782	CB	17.25 x 16.94 x 10.25	275	KLR600ECB5
	KLR750ECB	700	750	929	CB	18.00 x 18.00 x 13.00	260	KLR750ECB7
	KLR850ECB	800	850	1007	CB	18.00 x 18.00 x 12.00	290	KLR850ECB7
	KLR950ECB	900	950	1100	CB	18.00 x 18.00 x 12.00	290	KLR950ECB7


*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

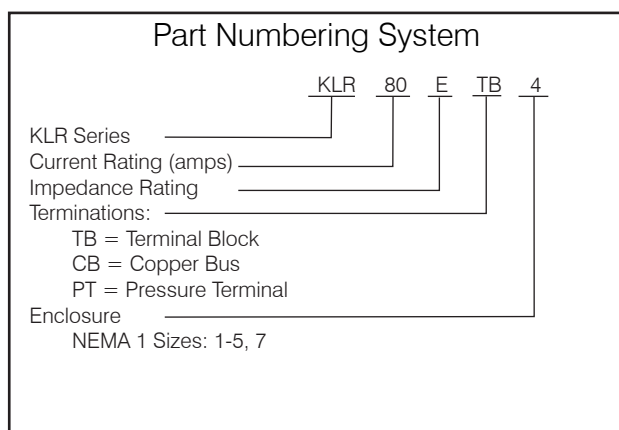

KLR Series Three Phase Reactors

575 Volt 5% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	UL Type 1 Enclosed		UL Type 3R Enclosed	
					Part Number *		Part Number *	
	KLRUL2ETB	1	2	13	KLRUL2ETBE01		KLRUL2ETBE3R	
	KLRUL3ETB	1.5 - 2	3	17	KLRUL3ETBE01		KLRUL3ETBE3R	
	KLRUL4ETB	3	4	27	KLRUL4ETBE01		KLRUL4ETBE3R	
	KLRUL6ETB	3	6	28	KLRUL6ETBE01		KLRUL6ETBE3R	
	KLRUL8ETB	5	8	48	KLRUL8ETBE01		KLRUL8ETBE3R	
	KLRUL12ETB	7.5	12	56	KLRUL12ETBE01		KLRUL12ETBE3R	
	KLRUL16ETB	10	16	67	KLRUL16ETBE01		KLRUL16ETBE3R	
	KLRUL18ETB	15	18	73	KLRUL18ETBE01		KLRUL18ETBE3R	
	KLRUL21ETB	15	21	69	KLRUL21ETBE01		KLRUL21ETBE3R	
	KLRUL25ETB	20	25	92	KLRUL25ETBE01		KLRUL25ETBE3R	
	KLRUL27ETB	25	27	94	KLRUL27ETBE01		KLRUL27ETBE3R	
	KLRUL35ETB	30	35	125	KLRUL35ETBE01		KLRUL35ETBE3R	
	KLRUL45ETB	40	45	146	KLRUL45ETBE01		KLRUL45ETBE3R	
	KLRUL55ETB	50	55	132	KLRUL55ETBE01		KLRUL55ETBE3R	
	KLRUL80ETB	60 - 75	80	178	KLRUL80ETBE01		KLRUL80ETBE3R	
	KLRUL110EPT	100	110	259	KLRUL110EPT E01		KLRUL110EPT E3R	
	KLRUL130EPT	125	130	287	KLRUL130EPT E01		KLRUL130EPT E3R	
	KLRUL160EPT	150	160	299	KLRUL160EPT E01		KLRUL160EPT E3R	
	KLRUL200EPT	200	200	349	KLRUL200EPT E01		KLRUL200EPT E3R	
	KLRUL250EPT	250	250	375	KLRUL250EPT E01		KLRUL250EPT E3R	
	KLRUL300EPT	300	300	422	KLRUL300EPT E01		KLRUL300EPT E3R	
	KLRUL360EPT	350	360	463	KLRUL360EPT E01		KLRUL360EPT E3R	
	KLRUL420EPT	400	420	532	KLRUL420EPT E01		KLRUL420EPT E3R	
	KLRUL480EPT	500	480	576	KLRUL480EPT E01		KLRUL480EPT E3R	
	KLRUL600EPT	600	600	782	KLRUL600EPT E01		KLRUL600EPT E3R	
	KLRUL750EPT	700	750	929	KLRUL750EPT E01			
	KLRUL850EPT	800	850	1007	KLRUL850EPT E01			
	KLRUL950EPT	900	950	1100	KLRUL950EPT E01			

Part Numbering System

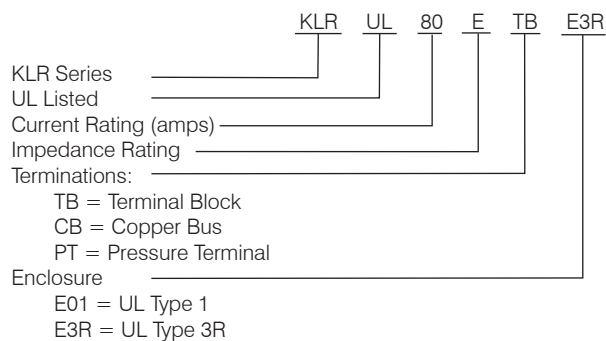


KLR Series Three Phase Reactors

Part Number	NEC Motor HP	Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed Part Number *
					Height x Width x Depth	Wgt	
KLR2DQDV	1	2	9	QD	4.00 x 4.18 x 3.75	4	KLR2DQD1V
KLR3DQDV	1.5 - 2	3	12	QD	4.00 x 4.18 x 3.75	4	KLR3DQD1V
KLR4DQDV	3	4	18	QD	4.00 x 4.18 x 3.75	4	KLR4DQD1V
KLR6DQDV	3	6	22	QD	4.00 x 4.18 x 3.75	5	KLR6DQD1V
KLR8DQDV	5	8	28	QD	5.00 x 6.00 x 4.00	7	KLR8DQD1V
KLR12DQDV	7.5	12	44	QD	5.00 x 6.00 x 4.00	7	KLR12DQD1V
KLR16DRLV	10	16	52	RL	5.00 x 6.00 x 4.50	8	KLR16DRL1V
KLR18DRLV	15	18	44	RL	5.75 x 7.20 x 5.00	12	KLR18DRL2V
KLR21DRLV	15	21	51	RL	5.75 x 7.20 x 5.00	13	KLR21DRL2V
KLR25DRLV	20	25	72	RL	5.75 x 7.20 x 5.00	13	KLR25DRL2V
KLR27DRLV	25	27	62	RL	5.75 x 7.20 x 5.00	13	KLR27DRL2V
KLR35DRLV	30	35	79	RL	5.75 x 7.20 x 5.12	16	KLR35DRL3V
KLR45DRLV	40	45	90	RL	7.00 x 9.00 x 6.00	26	KLR45DRL3V
KLR55DRLV	50	55	90	RL	7.00 x 9.00 x 6.00	24	KLR55DRL3V
KLR80DRLV	60 - 75	80	116	RL	9.00 x 11.00 x 7.50	49	KLR80DRL4V
KLR110DCBV	100	110	217	CB	9.00 x 11.00 x 7.50	49	KLR110DCB4V
KLR130DCBV	125	130	242	CB	9.00 x 11.00 x 7.50	47	KLR130DCB4V
KLR160DCBV	150	160	261	CB	9.00 x 11.00 x 7.50	47	KLR160DCB4V
KLR200DCBV	200	200	270	CB	11.38 x 14.00 x 9.31	86	KLR200DCB5V
KLR250DCBV	250	250	316	CB	11.38 x 14.00 x 9.31	91	KLR250DCB5V
KLR300DCBV	300	300	335	CB	11.38 x 14.00 x 9.31	101	KLR300DCB5V
KLR360DCBV	350	360	420	CB	11.38 x 14.00 x 9.31	98	KLR360DCB5V
KLR420DCBV	400	420	435	CB	11.38 x 14.00 x 9.31	100	KLR420DCB5V
KLR480DCBV	500	480	395	CB	11.38 x 15.00 x 13.00	175	KLR480DCB5V
KLR600DCBV	600	600	580	CB	11.38 x 15.00 x 13.00	151	KLR600DCB5V
KLR750DCBV	700	750	604	CB	18.00 x 18.00 x 13.00	270	KLR750DCB7V
KLR850DCBV	800	850	703	CB	18.00 x 18.50 x 14.25	275	KLR850DCB7V
KLR950DCBV	900	950	773	CB	18.00 x 18.50 x 14.25	280	KLR950DCB7V

Notes:

- For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.
- UL Listed available upon request.

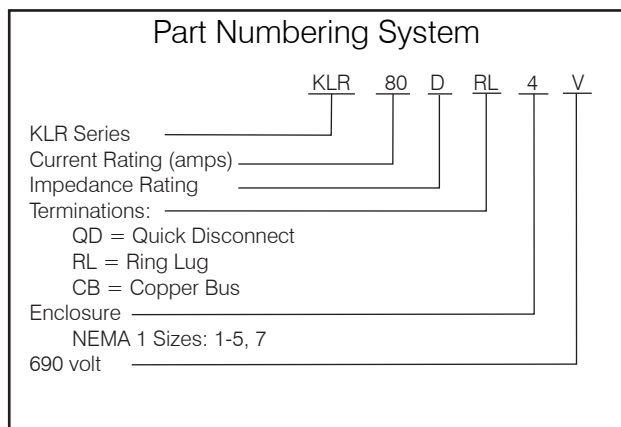

KLR Series Three Phase Reactors

690 Volt 5% Z	Part Number	NEC Motor HP	Rated Amps	Watts Loss	Stand. Terms	Dimensions (in.)		NEMA 1 Enclosed
						Height x Width x Depth	Wgt	Part Number *
	KLR2EQDV	1	2	13	QD	4.00 x 4.18 x 3.75	4	KLR2EQD1V
	KLR3EQDV	1.5 - 2	3	17	QD	4.00 x 4.18 x 3.75	5	KLR3EQD1V
	KLR4EQDV	3	4	27	QD	4.00 x 4.18 x 3.75	5	KLR4EQD1V
	KLR6EQDV	3	6	28	QD	5.00 x 6.00 x 4.00	7	KLR6EQD1V
	KLR8EQDV	5	8	48	QD	5.00 x 6.00 x 4.00	7	KLR8EQD1V
	KLR12ERLV	7.5	12	56	RL	5.75 x 7.20 x 5.00	8	KLR12ERL2V
	KLR16ERLV	10	16	67	RL	5.75 x 7.20 x 5.00	13	KLR16ERL2V
	KLR18ERLV	15	18	73	RL	5.75 x 7.20 x 5.12	17	KLR18ERL3V
	KLR21ERLV	15	21	69	RL	5.75 x 7.20 x 5.12	17	KLR21ERL3V
	KLR25ERLV	20	25	92	RL	7.00 x 9.00 x 6.00	17	KLR25ERL3V
	KLR27ERLV	25	27	94	RL	7.00 x 9.00 x 6.00	17	KLR27ERL3V
	KLR35ERLV	30	35	125	RL	7.00 x 9.00 x 6.00	23	KLR35ERL3V
	KLR45ERLV	40	45	146	RL	9.00 x 11.00 x 6.50	26	KLR45ERL4V
	KLR55ERLV	50	55	132	RL	9.00 x 11.00 x 7.50	33	KLR55ERL4V
	KLR80ERLV	60 - 75	80	178	RL	9.00 x 11.00 x 7.50	49	KLR80ERL4V
	KLR110ECBV	100	110	259	CB	11.38 x 14.00 x 9.31	82	KLR110ECB5V
	KLR130ECBV	125	130	287	CB	11.38 x 14.00 x 9.31	82	KLR130ECB5V
	KLR160ECBV	150	160	299	CB	11.38 x 14.00 x 9.31	89	KLR160ECB5V
	KLR200ECBV	200	200	349	CB	11.38 x 14.00 x 9.31	110	KLR200ECB5V
	KLR250ECBV	250	250	375	CB	11.38 x 14.00 x 10.00	115	KLR250ECB5V
	KLR300ECBV	300	300	422	CB	11.38 x 15.00 x 13.00	156	KLR300ECB5V
	KLR360ECBV	350	360	463	CB	11.38 x 15.00 x 13.00	160	KLR360ECB5V
	KLR420ECBV	400	420	532	CB	11.38 x 15.00 x 13.00	170	KLR420ECB5V
	KLR480ECBV	500	480	576	CB	11.38 x 15.00 x 13.00	175	KLR480ECB5V
	KLR600ECBV	600	600	782	CB	16.50 x 21.00 x 13.00	275	KLR600ECB7V
	KLR750ECBV	700	750	929	CB	18.00 x 18.00 x 13.00	260	KLR750ECB7V
	KLR850ECBV	800	850	1007	CB	18.00 x 18.50 x 14.25	290	KLR850ECB7V
	KLR950ECBV	900	950	1100	CB	18.00 x 18.50 x 14.25	290	KLR950ECB7V

*For enclosed unit dimensions and added weight, please refer to the Reactor Enclosure Price page.

Note: UL Listed available upon request.

