


Temperature measurement Accessories thermowell THW-3-G1/2-A4-L100

TURCK
works

Industrial
Automation

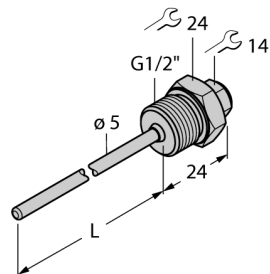

- Thermowell for mounting TS203 probes
- Process connection G1/2" male thread

General description

Thermowells are used for unpressurized mounting of probes. They protect the probes against direct contact with the medium. The probe can be replaced without interrupting the process.

Type designation

Ident-No.

THW-3-G1/2-A4-L100

9910444

Temperature range

Temperature operating range

-50...350 °C

Temperature operating range

-58...662 °F

Immersion depth (L)

100 mm

Housing

Housing material

Stainless steel 1.4404 (AISI 316L), V4A (1.4404)

Internal diameter

3.5 mm

Process connection

G 1/2" male thread

Pressure resistance

400 bar

Max. tightening torque housing nut

100 Nm