


Data sheet

Commercial Art.No.: Z1.299.4155.0

fuse holder SIST-LED /V0

Fuse holder to stick on disconnect base block type WK 4 TKG..., with LED- indicator 12-24 V, for fuse 5x20mm, color: grey

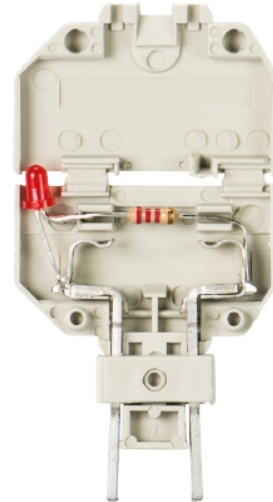

Commercial Art.No.	Z1.299.4155.0
EAN	4015573528277
Order Unit	10

certificates / approvals



Technical data

general

color	grey
width/grid dimension	6 mm
insulating housing	PA666
flammability class of insulation material acc. with UL94	V0
mounting method	direct mounting
fuse insert	G-fuse 5x20 mm
Montageart	direct mounting
Brennbarkeitsklasse des Isolierstoffs	V0

technical data

rated voltage	250 V
closing plate required	no
type of insulation material	thermoplastic
length	32.5 mm

additional data

remark to rated voltage	note fuse insert
remark to rated current	note fuse insert
defect indicator	LED
voltage type for defect indication	AC/DC
minimum operating voltage of defective display	12 V

maximum operating voltage of defective display	24 V
--	------

classification

ECLASS 11	
ECLASS 8.1	27141116
ETIM 9.0	EC000899
ETIM 8.0	EC000899
ETIM 7.0	EC000899
ETIM 6.0	EC000899
ETIM 5.0	EC000899
ETIM 4.0	EC000899
ETIM 3.0	EC000899

product compliance

ROHS conformity status	compliant/exempted
ROHS exceptions	III-6(c)
REACH-SVHC conformity status	compliant

Accessories

Commercial Art.No.:	Article-type description:	Description:
------------------------	---------------------------	--------------

